

MOTOROLA SOLUTIONS **DLR Series Two-Way Radio**

Authorized Business Radio Reseller



The ability to communicate and solve problems in real time is the cornerstone of good business operations. With the Motorola® DLR Series digital radio, your team can quickly and easily communicate to improve operational efficiencies, solve problems rapidly, address unexpected situations and improve customer satisfaction. This lightweight radio, with its sleek styling, is a simple yet powerful collaboration tool. Its unique features will take your organization to a new level of performance and operational excellence.



Features:

- **Coverage** - up to 300,000 sq ft and 20 floors
- **Battery Life** - up to 14 hours
- **No FCC licensing required**
- **Programmable Button** - allows for direct reply, direct call, page all available, call all available or instant mute
- **Digital Audio Quality** - stays louder and clearer everywhere you have coverage
- **Digital Technology** - only compatible with DTR Series radios; **NOT** compatible with analog radios (CLS, CLP, RM or RDX)

Order No.	Mfr. No.	No. of Channels	Power (W)	Frequency Range	Net Price
MA111908948	DLR1020	2	1	900 MHz ISM Frequency-Hopping Spread Spectrum	\$209.00
MA111908951	DLR1060	6	1	900 MHz ISM Frequency-Hopping Spread Spectrum	219.00

MOTOROLA SOLUTIONS **Two-Way Radio Accessories**

Authorized Business Radio Reseller

For additional Motorola OEM two-way radio accessories not shown below including batteries, remote speaker microphones, belt clips, charging trays, antennas and more for ALL Motorola radios, please contact your local Applied® service center.



Use With	Order No.	Mfr. No.	Accessory Type	Net Price
CLS Series	MA101856534	56531	Multi-Unit Charger	\$169.23
	MA101568330	SNN5571	Li-Ion Rechargeable Battery	35.38
DTR Series	MA102110131	53960	Multi-Unit Charger	161.54
	MA101586571	SNN5706	High Capacity Battery	40.77
RDX Series	MA101569025	RLN6302	Leather Carrying Case	50.77
	MA101548748	RLN6308	Ultra High Capacity Battery	101.54
	MA101548747	RLN6309	Multi-Unit Charger	253.85
	MA101477818	RLN6351	Standard Capacity Battery	76.92
RM Series	MA110305072	PMNN4434	Li-Ion 2150 MAH Battery	60.00
	MA110305071	PMLN6394	Single-Unit Charger	32.31
	MA110305070	PMLN6384	Multi-Unit Charger	269.23
	MA110305054	HKKN4028	Radio-To-Radio Cloning Cable	18.46
RDX, RM and DLR Series	MA110305061	HKLN4510	Carry Holster With Swivel Belt Clip	16.15
	MA110305053	HKKN4027	Customer Programming Software (CPS) Cable	36.92
CLS, DTR, RDX or RM Series	MA102147388	HKLN4477	Surveillance Earpiece w/ PTT Microphone	41.54
	MA101603381	RLN6423	Swivel Earpiece w/ PTT Microphone	26.92
	MA101467420	HMN9026	Remote Speaker Microphone	57.69
	MA101858201	56517	Earpiece Microphone	24.62
DLR Series	MA111909073	HKLN4615	Belt Clip	18.46
	MA111909077	PMLN7136	Multi-Unit Charger	376.92
	MA111909078	PMLN7140	Single Unit Battery Charger	41.54
DP, CLP and SL Series	MA110305064	HKNN4013	High Capacity Battery	34.62

MOTOROLA, MOTO, MOTOROLA SOLUTIONS, and the Stylized M logo are trademarks or registered trademarks of Motorola Trademark Holdings, LLC and are used under license. All other trademarks are the property of their respective owners. ©2016 Motorola Solutions, Inc. All rights reserved.

TPI Corporation **Circulator Fan Head**
America's Comfort Conditioning Company



Features:

- Two-speed, 120 V, single phase, ball bearing, totally enclosed, permanently lubricated, permanent split capacitor motor
- Pull chain switch
- Double-locking, chrome-plated steel guard
- Blades have steel hub and aluminum paddles


Compliances:

- ETL C/U.S. listed
- Meets OSHA standards

Single Phase

Order No.	Mfr. No.	Size (in)	Motor (hp)	Amps	Air Movement Low (cfm)	Air Movement High (cfm)	Net Price
MA101639886	ACH24	24	1/4	2.5	5,000	6,800	\$226.98
MA101654123	ACH30	30	1/4	2.7	6,000	7,900	235.43
MA101626662	IHP24H	24	1/3	3.0	5,200	7,000	287.82
MA101639885	IHP30H	30	1/3	3.4	6,200	8,200	300.68

TPI Corporation **Circulator Fan Mount**
America's Comfort Conditioning Company

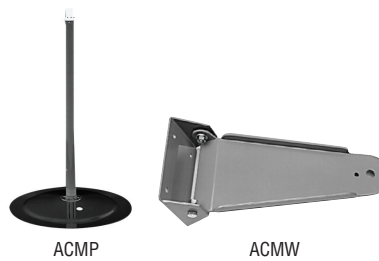

Features:

- Pedestal pole adjusts the center of the fan from 52" to 78" and bolts to a 27" diameter steel dome base with five carriage bolts

Note:

- Mounts will fit any size TPI fan head (24" or 30")

Order No.	Mfr. No.	Fan Mount Type	Net Price
MA101667162	ACMP	Pedestal Mount	\$126.84
MA102075648	ACMW	Wall Mount	46.56

