



## FLUORESCENT BALLAST SPECIFICATIONS

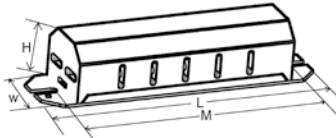
### DESCRIPTION

Model No.	Ballast Type	Starting Type	Qty of Lamps	Lamp Type
BL-2040CB-2	ELECTRONIC	INSTANT START	2	1x FC6T9, FC8T9 & 1x FC10T9, FC12T9, FC16T9

### ELECTRICAL CHARACTERISTICS

Input Voltage	Frequency	Lamp Watts	Input Watts	Input Current	THD	Power Factor	Sound Rated
120	60Hz	22W & 32W	45.5W	<0.73A	<140%	>0.55	A
Min. Starting Temp	Heat Protection Level	Outdoor Type	Open Circuit Voltage	Ballast Frequency	NO PCBs		
0°F/-18°C	CLASS P	TYPE 1	600V	>40KHZ			

### PHYSICAL CHARACTERISTICS

	CASE DIMENSIONS					
	Units	M	L	W	H	
	Inch	5.57	6.71	1.75	1.31	
	TOL(+/-)	0.05	0.05	0.05	0.05	
LEAD LENGTH						
Unit	Black	White	Red	Yellow	Green	Blue
Inch	9.85	9.85	4.73	7.09	7.09	4.73
TOL(+/-)	+0.5, -0	+0.5, -0	+0.5, -0	+0.5, -0	+0.5, -0	+0.5, -0

### BALLAST LABEL

 <p><b>120V - 60Hz</b> INPUT CURRENT 0.73A</p> <p>LISTED FLUORESCENT BALLAST 22VE</p> <p>E244627 1108</p> <p><a href="http://www.innovativelighting.cn">www.innovativelighting.cn</a></p>	<p>USE FOR 2 LAMPS One FC6T9(20W),FC8T9(22W) And One FC10T9(30W),FC12T9(32W) FC16T9(40W) Instant Start No PCBs Normal Power Factor UL LISTED CLASS P. OUT DOOR TYPE1</p> <p><b>CAUTION:</b> Disconnect All Input Power Before Installing Or Servicing.</p>	<p style="text-align: center;"><b>Electronic Ballast</b></p> <p style="text-align: center;">CAT:2040 MODEL:BL-2040CB-2</p> 
--	--	---

### USPAR ENTERPRISES INC.

ADD: 13404 Monte Vista Ave Chino, CA 91710  
WEBSITE: [www.uspar.com](http://www.uspar.com)

TEL: 1-909-591-7506  
FAX 1-909-590-3220