


# Sensors Accessories

## Quick Mount

Part Number	ID Number	Features	Dimensions					
			A	B	C	D	E	F
QM-08	A2511		0.32 [8.18]	1.28 [32.4]	0.69 [17.5]	M12x1	0.15 [3.85]	0.67 [16.9]
QM-08L	A2512	Ext. Length		1.90 [48.0]	1.34 [34.0]			
QM-08L-T	A9441	Ext. Length, Teflon		1.90 [48.0]	1.34 [34.0]			
QM-12	A2513		0.48 [12.1]	1.34 [33.7]	0.77 [19.5]	M16x1	0.16 [4.01]	0.86 [21.8]
QM-12L	A2514	Ext. Length		1.76 [44.8]	1.18 [30.0]			
QM-12L-T	A2542	Ext. Length, Teflon		1.76 [44.8]	1.18 [30.0]			
QM-18	A2515		0.71 [18.1]	1.52 [38.5]	0.79 [20.0]	M24x1.5	0.19 [4.95]	1.18 [30.0]
QM-18L	A2516	Ext. Length		2.28 [58.0]	1.57 [40.0]			
QM-18L-T	A2543	Ext. Length, Teflon		2.28 [58.0]	1.57 [40.0]			
QM-30	A2517		1.19 [30.1]	1.50 [35.0]	0.79 [20.0]	M36x1.5	0.24 [6.13]	1.61 [41.0]
QM-30L	A2518	Ext. Length		2.28 [58.0]	1.57 [40.0]			
QM-30L-T	A2544	Ext. Length, Teflon		2.28 [58.0]	1.57 [40.0]			

Inches [mm]

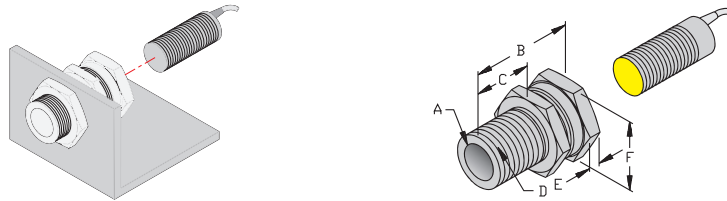

## Cushion Mount

Part Number	ID Number	Dimensions									
		A (INSIDE THREAD)	B (OUTSIDE THREAD)	C (MAX.)	D (Across FLATS)	E (MAXIMUM ALLOWABLE OVERTRAVEL)	F	G	H	J	K
CM-08 CM-08N	A2503 A2504	M8x1	M16x1.5	.433 [11.0]	.875 [22.2]	.395 [10.0]	.750 [19.1]	.155 [3.94]	.200 [5.08]	.600 [15.2]	.0004 [.010]
CM-12 CM-12N	A2505 A2506	M12x1	M22x1.5	.433 [11.0]	1.19 [30.2]	.395 [10.0]	.750 [19.1]	.155 [3.94]	.245 [6.22]	.860 [21.8]	.010 [.250]
CM-18 CM-18N	A2507 A2508	M18x1	M30x1.5	.598 [15.2]	1.38 [35.1]	.395 [10.0]	1.00 [25.4]	0.02 [5.08]	.315 [8.00]	1.18 [30.0]	.001 [.035]
CM-30 CM-30N	A2509 A2510	M30x1.5	M47x1.5	.972 [24.7]	2.05 [52.1]	.591 [15.0]	1.37 [34.9]	0.20 [5.08]	.315 [8.00]	1.75 [44.5]	.035 [.890]

Stainless versions available (\*NSS)

Material:

Cap: Plastic

Housing: Anodized aluminum

