
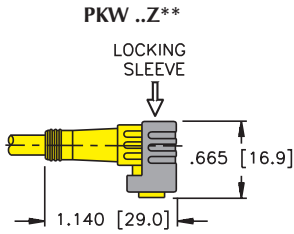


3-Wire picofast® Cordsets, Snap Lock (Locking Sleeve)

- Right Angle Female Connectors
- NEMA 1, 3, 4, 6P and IEC IP 67 Protection
- 125 VAC/VDC, 4 A

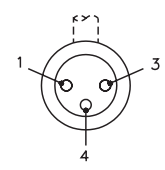

Housing Style	Part Number	Cable	Features	Pinout
 <p>PKW ..Z** LOCKING SLEEVE</p>	PKW 3Z-*	AWM PVC Yellow 3x24 AWG 105°C 4.4 mm OD Cable #RF50642-*M [†]	<i>flexlife</i> ®	 <p>1. BN 3. BU 4. BK</p>
	PKW 3Z-*/S90	AWM PUR Black 3x24 AWG 105°C 4.4 mm OD Cable #RF50587-*M [†]	<i>Cut/Abrasion Immune</i>	
	PKW 3Z-*/S90/S101	AWM PUR Black 3x26 AWG 105°C 4.4 mm OD Cable #RF50723-*M [†]	<i>Cut/Abrasion Immune, flexlife-10, High Flex - Over 10 Million Cycles</i>	
	PKW 3Z-*/S90/S618	AWM PUR Black 3x24 AWG 105°C 4.4 mm OD Cable #RF50601-*M [†]	<i>Cut/Abrasion Immune, EMI/RFI Protection</i>	
	PKW 3Z-*/XOR	PVC Orange 3x24 AWG 80°C, 250°C short term 4.4 mm OD Cable #RF04449-*M [†]	<i>Weld Flash Immune, High Temp. Immune</i>	
	PKW 3Z-*/S760	AWM PVC Black 3x24 AWG 105°C 4.4 mm OD Cable #RF50585-M [†]	<i>flexlife</i>	

* Length in meters. Standard cable lengths are 2, 4, 6, 8 and 10 meters.

** Standard coupling material is POM.."PKG..Z".

† See Section N for *reelfast*® cable information.