
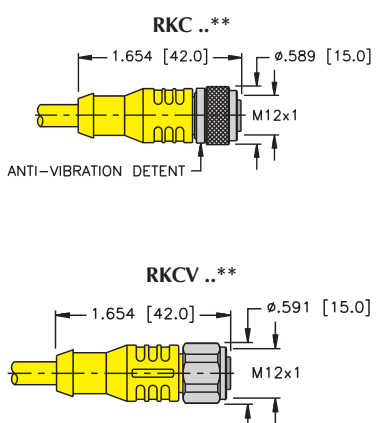


10-Wire M12 eurofast® Cordsets, "C" Style Medium Plug Body

- Straight Female Connector
- NEMA 1, 3, 4, 6P
- IEC IP 68 Protection
- 60 VAC/75 VDC, 2 A

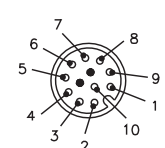

| Housing Style | Part Number | Cable | Features | Pinout |
|--|----------------|--|--|---|
|  | RKC 10T-* | AWM PVC Grey 10x24 AWG 105°C 6.2 mm OD Cable #RF51004-*M† | <i>flexlife</i> ® |  |
| | RKC 10T-*/S90 | AWM PUR Grey 10x24 AWG 105°C 6.2 mm OD Cable #RF51005-*M† | <i>Cut/Abrasion Immune</i> | |
| | RKC 10T-*/S101 | AWM TPE Black 10x24 AWG 105°C 7.0 mm OD Cable #RF51077-*M† | <i>flexLife-10, High Flex Over 10 Million Cycles</i> | |
| | RKC 10T-*/S618 | AWM PVC Black 10x24 AWG Foil/Drain 105°C 7.0 mm OD Cable #RF51076-*M† | <i>RFI/EMI Shielding</i> | |

Cordsets

* Length in meters. Standard cable lengths are 2, 4, 6, 8 and 10 meters. Consult factory for other lengths.
 ** Standard coupling nut material is nickel plated brass "RKC ."; "RKC V ." indicates 316 stainless steel.
 † See Section N for **reelfast**® cable information.