

 


minifast® Standard Duty Cordsets, PVC


- High Grade Oil & UV Resistant PVC
- Standard Color Code
- 18 AWG
- Available in 2 - 6 Conductors




See table below




RKM ..

 

WKM ..

 

RSM ..

 

WSM ..

2-pin, 300 V, 9.0 A

Female

Male

Application	Cable Specs	Pinout	Straight	Right Angle	Straight	Right Angle
Standard duty for 2-wire applications UL Recognized CSA Certified	2/18 AWG Yellow PVC 105°C 7.3 mm OD	1. Bn 2. Bu	RKM 20-*M	WKM 20-*M	RSM 20-*M	WSM 20-*M

3-pin, 300 V, 9.0 A

Female

Male

Application	Cable Specs	Pinout	Straight	Right Angle	Straight	Right Angle
Standard duty for 2-wire AC w/Ground UL Recognized CSA Certified	3/18 AWG Yellow PVC 105°C 7.3 mm OD	1. Gn/Ye 2. Bn 3. Bu	RKM 30-*M	WKM 30-*M	RSM 30-*M	WSM 30-*M
Standard duty for 3-wire applications UL Recognized CSA Certified	3/18 AWG Yellow PVC 105°C 7.3 mm OD	1. Bk 2. Bn 3. Bu	RKM 31-*M	WKM 31-*M	RSM 31-*M	WSM 31-*M

4-pin, 300 V, 9.0 A

Female

Male

Application	Cable Specs	Pinout	Straight	Right Angle	Straight	Right Angle
Standard duty for 4-wire applications UL Recognized CSA Certified	4/18 AWG Yellow PVC 105°C 7.3 mm OD	1. Bn 2. Wh 3. Bu 4. Bk	RKM 40-*M	WKM 40-*M	RSM 40-*M	WSM 40-*M

5-pin, 300 V, 9.0 A

Female

Male

Application	Cable Specs	Pinout	Straight	Right Angle	Straight	Right Angle
Standard duty for 5-wire applications UL Recognized CSA Certified	5/18 AWG Yellow PVC 105°C 7.3 mm OD	1. Bk 2. Bu 3. Gn/Ye 4. Bn 5. Wh	RKM 50-*M	WKM 50-*M	RSM 50-*M	WSM 50-*M

6-pin, 300 V, 9.0 A

Female

Male

Application	Cable Specs	Pinout	Straight	Right Angle	Straight	Right Angle
Standard duty for 6-wire applications	6/18 AWG Yellow PVC 105°C 7.3 mm OD	1. Gn 2. Wh 3. Bu 4. Gy 5. Ye 6. Bn	RKM 61-*M	WKM 61-*M	RSM 61-*M	WSM 61-*M





* = Length in meters.

Specifications

Connector:	Oil resistant polyurethane body material, PUR contact carrier.
Contacts:	Gold plated brass.
Coupling Nuts:	Nickel plated brass. (see options below)**
Cable:	See table.
Protection:	NEMA 1, 3,4, 6P and IEC IP67.
Cable Length:	Standard cable lengths are nominal 2, 4 and 6 meters. Other lengths available by request - consult factory.

**** Options:** To specify nylon coupling nut, omit the "M" from the part number.
 For example: WKM .. to WK .. (right angle female) or RSM .. to RS .. (straight male).
 To specify stainless steel coupling nut, change the "M" to a "V" in the part number.
 For example: RKM .. to RKV .. (straight female) or WSM .. to WSV .. (right angle male).

Dimensions

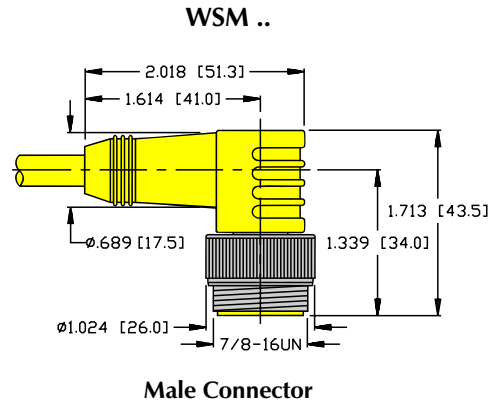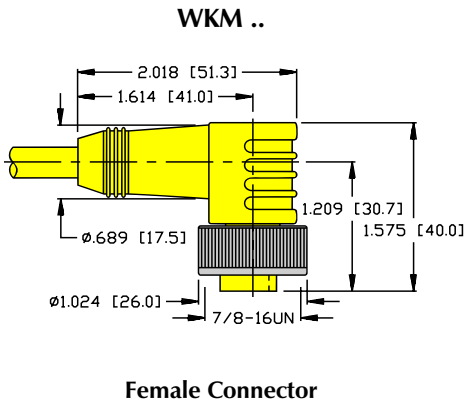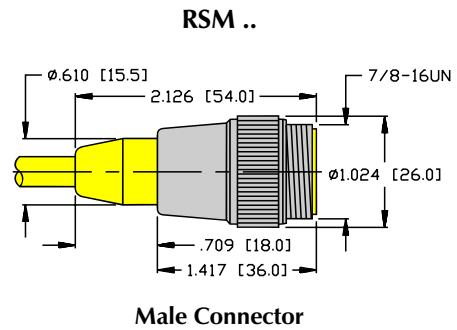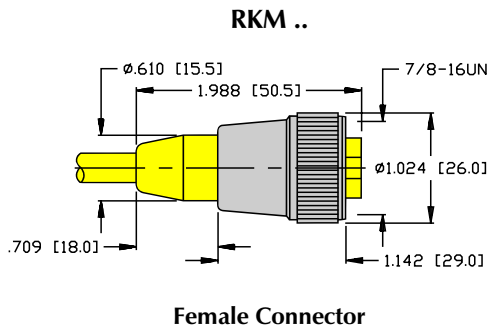

Pinouts

Female					Male				
2-pin	3-pin	4-pin	5-pin	6-pin	2-pin	3-pin	4-pin	5-pin	6-pin