




U-CONDUIT

U-Conduit

C14.1

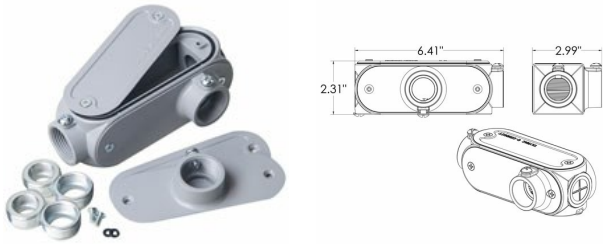

Catalog #: UCB0100

APPLICATIONS

The U-Conduit Body is for use with Rigid/IMC or EMT conduit, for pulling access or to split a run into multiple directions. Patented interchangeable panels easily configure to all standard conduit bodies: LB, LR, LL, C, and T. TayMac Universal Conduit Bodies are suitable for weatherproof installs.

PRODUCT FEATURES

- Seamless pre-affixed gasket and self-aligning covers/panels
- More wiring capacity than standard bodies and meets 2014 NEC 314.16(C)(2) for volume marking
- Lightweight, durable TayMac TUFF™ Die Cast Aluminum construction
- Tri-combo head set screws
- Captive screws with attached O-ring for ease of use and a weatherproof seal
- Includes (1) body, (3) blank covers/panels, (1) T panel, (1) LL/LB/LR panel, (2) 3/4" reducer bushings, (2) 1/2" reducer bushings, (1) closure plug and extra hardware
- Ideal for service trucks and reduces inventory
- Not suitable for use in hazardous location applications

CULUS

Listed

NEMA

NEMA 3R Rated

NEC

2014 NEC Compliant

U.S. PATENT

8,242,386 B1

GENERAL PRODUCT INFORMATION

Trade Size: 1"

PACKAGING

Package Type:	Carton
Std. Pkg.:	10
Ship Carton Qty.:	10
Product UPC-A Labeled:	Yes
Ship Carton Length (in.):	17.50
Ship Carton Width (in.):	7.00
Ship Carton Height (in.):	5.50
Ctn Weight (Lbs.):	17.10
Pallet Qty:	1120
UPC Number:	050169571248
I2of5:	50050169571243