

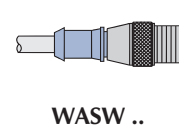


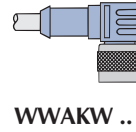


eurofast® Cordsets and Extensions, Reverse Key

- PVC Cable
- Reverse Key (Type "B" coded keyway)
- Unshielded
- Primarily Used for AC

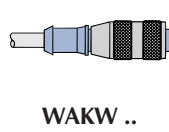


5-Pin, Reverse Key, 250 V, 4.0 A

Application	Cable Specs	Pinout	Female		Male	
			Straight	Right Angle	Straight	Right Angle
Reverse key for 2-wire AC with ground UL Recognized CSA Certified	3/20 AWG Grey PVC 105°C 5.2 mm OD	1. Bn 2. Bu 3. N/C 4. Gn/Ye 5. N/C	WAKW 4T-*/S626	WWAKW 4T-*/S626	WASW 4T-*/S626	- - - -
Reverse key for 4-wire AC with ground UL Recognized CSA Certified	4/22 AWG, 1/20 AWG Grey PVC 105°C 5.7 mm OD	1. Bn 2. Wh 3. Bu 4. Bk 5. Gn/Ye	WAKW 4.5T-*	WWAKW 4.5T-*	WASW 4.5T-*	- - - -

 

WAKW .. WASW ..

 

WWAKW .. WASW ..

5-pin, Reverse Key Extensions, 250 V, 4.0 A

Application	Cable Specs	Straight Female Straight Male		Right Angle Female Straight Male	
		Reverse key for 2-wire AC with ground UL Recognized CSA Certified	3/20 AWG Grey PVC 105°C 5.2 mm OD	WAKW 4T-*/WASW 4T/S626	
Reverse key for 4-wire AC with ground UL Recognized CSA Certified	4/22 AWG, 1/20 AWG Grey PVC 105°C 5.7 mm OD	WAKW 4.5T-*/WASW 4.5T		WWAKW 4.5T-*/WASW 4.5T	


* = Length in meters

Specifications


Connector:	Oil resistant blue-grey polyurethane body material, Nylon contact carrier, spacings to VDE 0110 Group C.
Contacts:	Gold plated brass.
Coupling Nuts:	Nickel plated brass. See options below**.
Cable:	See table.
Protection:	NEMA 1,3,4,6P and IEC IP 68.
Cable Length:	Standard cable lengths are nominal 2, 4 and 6 meters. Other lengths available by request - consult factory.

**** Options:** To specify nylon coupling nut, add a "K" to part number.
 For example: WAKW .. to WAKKW .. (straight female) or WASW .. to WASKW .. (straight male).
 To specify stainless steel coupling nut, add a "V" to part number.
 For example: WAKW .. to WAKVW .. (straight female) or WASW .. to WASVW .. (straight male).


Dimensions

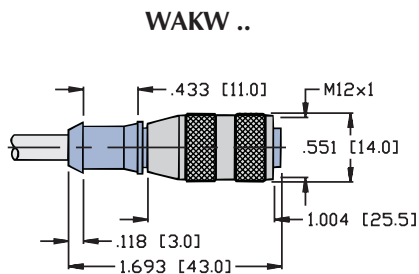

Female Connector

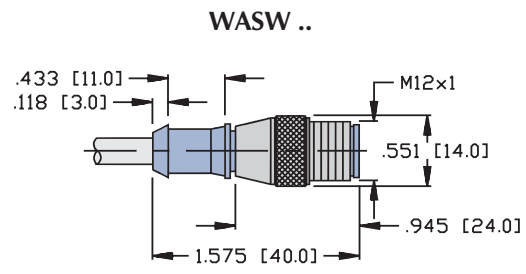

Male Connector

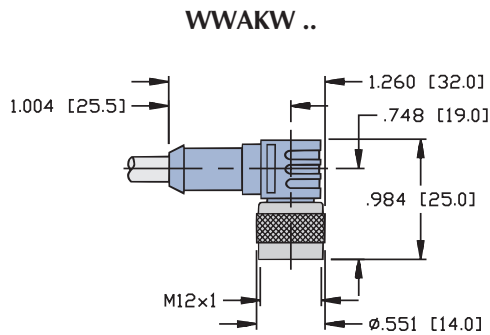

Female Connector

Pinouts

Female	Male
5-pin	5-pin