





## microfast® Standard Coiled Cordsets & Extensions, Unshielded PUR

- Unshielded
- Oil & Abrasion Resistant Polyurethane
- Coiled PUR in 3 Conductor

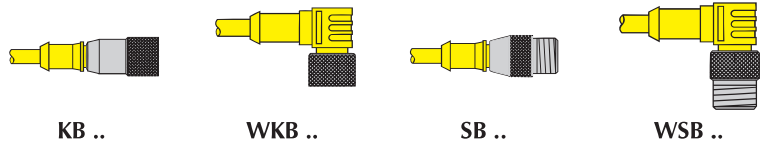

3-pin, 250 V, 4.0 A

Application	Cable Specs	Pinout	Female		Male	
			Straight	Right Angle	Straight	Right Angle
Retractable coil cord for repetitive motion, for 3-wire applications	3/22 AWG Yellow PUR 80°C 5.2 mm OD	1. Gn 2. Rd/Bk 3. Rd/Wh	KB 3T-3.3/S90-SP	WKB 3T-3.3/S90-SP	SB 3T-3.3/S90-SP	WSB 3T-3.3/S90-SP

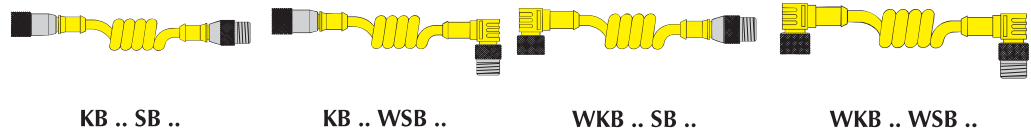

3-pin, 250 V, 4.0 A

Application	Cable Specs	Straight Female Straight Male	Straight Female Right Angle Male	Right Angle Female Straight Male	Right Angle Female Right Angle Male
		Retractable coil cord for repetitive motion, for 3-wire applications	3/22 AWG Yellow PUR 80°C 5.2 mm OD	KB 3T-3.3-SB 3T/S90-SP	KB 3T-3.3-WSB 3T/S90-SP


**Specifications**

- Connector:** Oil resistant polyurethane body material, Nylon contact carrier.
- Contacts:** Gold plated brass.
- Coupling Nuts:** Nickel plated brass, (see options below)\*\*.
- Cable:** See table.
- Protection:** NEMA 1,3,4,6P and IEC IP 67.
- Coiled Cord Length:** Extended length = 3.3 meters (approximate) Retracted length = 0.66 meters.


**\*\* Options:** To specify stainless steel coupling nut, add a "V" to part number.  
 For example: KB .. to KBV .. (straight female) or WSB .. to WSBV .. (right angle male).

**Dimensions**


**KB 3T-3.3-SB 3T/S90-SP**

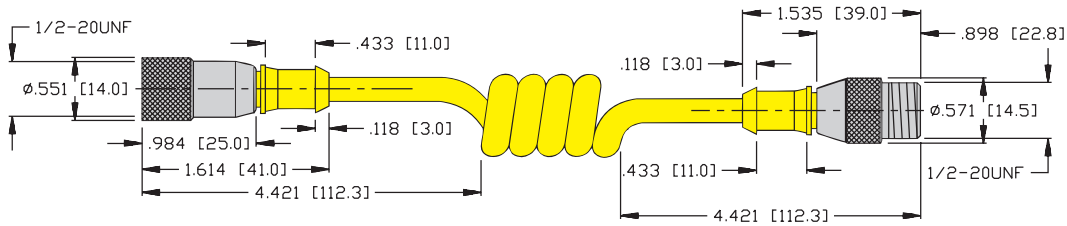

**WKB 3T-3.3-SB 3T/S90-SP**

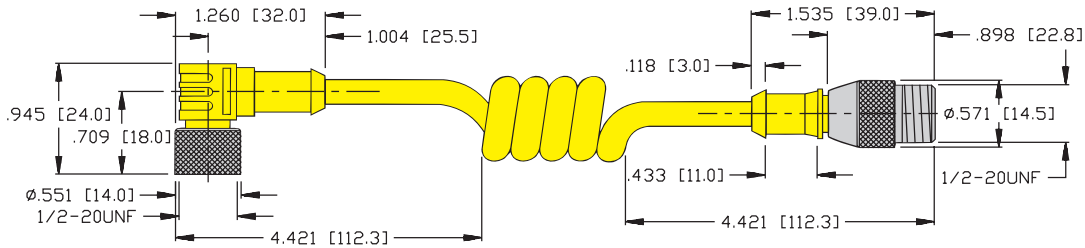

**..WSB ..**

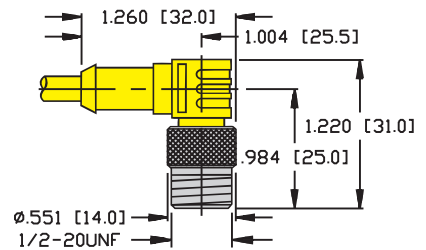

**Note:**  
 Replace right end of illustrations above with WSB shown at right for KB 3T-\*-WSB 3T/S90-SP and WKB 3T-\*-WSB 3T/S90-SP configuration.  
 Dimensions for coil and single ended styles remain the same.

**Male Connector**

**Pinouts**

Female	Male
<b>3-pin</b>	<b>3-pin</b>