


Specifications and Ordering Information for 3M™ CI Series Connectors up to 35 kV

Note: These 3M CI series connectors are for use with molded rubber splices.

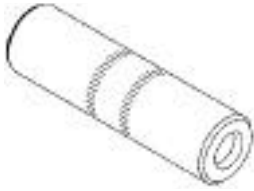

Product Number	Description	UPC (054007-)	Conductor Size Cu or Al		Length	Connector O.D.	Min. Order Case Qty.
			Stranded	Solid			
CI-22	Used with molded rubber splices	25636	4 AWG	2 AWG	2.0	0.63" (16 mm)	10 each
CI-2	Used with molded rubber splices	11651	2 AWG	1 AWG	2.0	0.63" (16 mm)	10 each
CI-21	Used with molded rubber splices	11856	2, 1 AWG	1, 1/0 AWG	2.0	0.63" (16 mm)	10 each
CI-21-840	Used with molded rubber splices	09136	2, 1 AWG	1, 1/0 AWG	3.0	0.90" (22 mm)	10 each
CI-1/0	Used with molded rubber splices	11867	1/0 AWG	—	2.0	0.63" (16 mm)	10 each
CI-1/0-840	Used with molded rubber splices	09137	1/0 AWG	—	3.0	0.90" (22 mm)	10 each
CI-2/0	Used with molded rubber splices	11875	2/0 AWG	—	3.0	0.91" (23 mm)	10 each
CI-3/0	Used with molded rubber splices	11883	3/0 AWG	—	3.0	0.90" (22 mm)	10 each
CI-4/0	Used with molded rubber splices	11891	4/0 AWG	—	3.0	0.90" (22 mm)	10 each
CI-250	Used with molded rubber splices	11909	250 kcmil	—	3.75	1.11" (28 mm)	10 each
CI-350	Used with molded rubber splices	11925	350 kcmil	—	3.70	1.11" (28 mm)	10 each
CI-450	Used with molded rubber splices	11933	500 kcmil Compact	—	4.25	1.3" (33 mm)	10 each
CI-500	Used with molded rubber splices	25644	500 kcmil	—	4.25	1.3" (33 mm)	10 each
CI-650	Used with molded rubber splices	11941	750 kcmil Compact	—	4.66	1.7" (43 mm)	10 each
CI-750	Used with molded rubber splices	25651	750 kcmil	—	4.66	1.57" (40 mm)	10 each