


Manual Motor Starters

Main Accessories

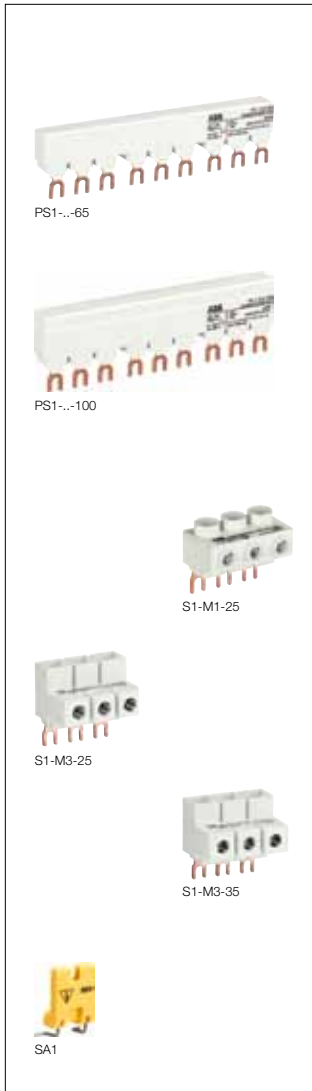

3-phase busbar systems

Manual Motor Starters		Number of MMS	Number of aux. contacts	Catalog number	List price	Pack ^(ing) pieces	Weight kg/lb (1 pce)
MS116	MS132						
3-phase busbar up to 65 A							
•	•	2	0	MS132-PS1-2-0-65		10	0.034/0.07
•	•	3	0	MS132-PS1-3-0-65		10	0.055/0.12
•	•	4	0	MS132-PS1-4-0-65		10	0.077/0.17
•	•	5	0	MS132-PS1-5-0-65		10	0.098/0.22
•	•	2	1	MS132-PS1-2-1-65		10	0.036/0.08
•	•	3	1	MS132-PS1-3-1-65		10	0.060/0.13
•	•	4	1	MS132-PS1-4-1-65		10	0.087/0.19
•	•	5	1	MS132-PS1-5-1-65		10	0.108/0.24
•	•	2	2	MS132-PS1-2-2-65		10	0.040/0.09
•	•	3	2	MS132-PS1-3-2-65		10	0.067/0.15
•	•	4	2	MS132-PS1-4-2-65		10	0.095/0.21
•	•	5	2	MS132-PS1-5-2-65		10	0.122/0.27

3-phase busbar up to 92 A

•	•	3	0	MS132-PS1-3-0-100		10	0.084/0.19
•	•	4	0	MS132-PS1-4-0-100		10	0.117/0.26
•	•	5	0	MS132-PS1-5-0-100		10	0.154/0.34
•	•	3	1	MS132-PS1-3-1-100		10	0.094/0.21
•	•	4	1	MS132-PS1-4-1-100		10	0.134/0.30
•	•	5	1	MS132-PS1-5-1-100		10	0.172/0.38
•	•	3	2	MS132-PS1-3-2-100		10	0.105/0.23

3-phase feeder terminals

Busbar types	Remarks	Connecting capacity AWG	Catalog number	List Price	Pack ^(ing) pieces	Weight kg/lb (1 pce)
65 A	92 A					
3-phase feeder terminals						
•	•	Flat	4	MS132-S1-M1-25	10	0.038/0.08
•	-	High	4	MS132-S1-M2-25	10	0.051/0.11
3-phase feeder terminals for CSA/UL type E						
•	•		4	MS132-S1-M3-25	10	0.042/0.09
•	•		2	MS132-S1-M3-35	10	0.060/0.13


Cover for 3-phase busbars

				MS132-BS1-3	50	0.003/0.01
--	--	--	--	-------------	----	------------

Locking

Manual Motor Starters		Catalog number	List Price	Pack ^(ing) pieces	Weight kg/lb (1 pce)
MS116	MS132				
Locking device					
•	-	Lock adapter	MS132-SA1	10	0.003/0.01
•	•	Padlock + 2 keys	MS132-SA2	10	0.020/0.04
•	-	Lock adapter + padlock + 2 keys	MS132-SA3	10	0.050/0.11

3-phase busbar up to 65 A

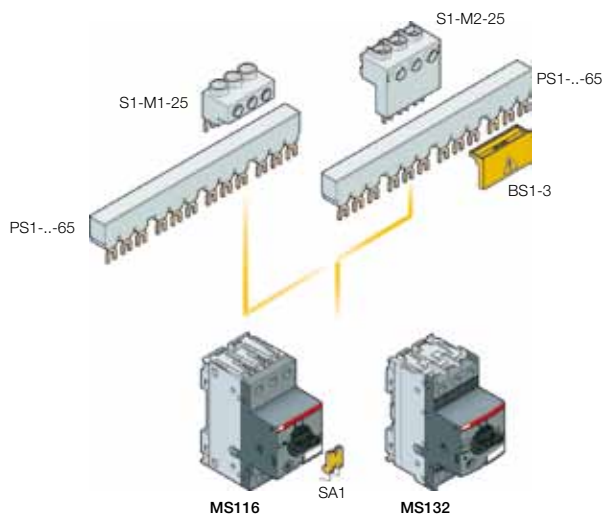

3-phase busbar up to 92 A

