

# Sta-Kon®



**Ring Terminal**  
**T&B Catalog Number:**

**UPC Number:**  
**Status:**  
**Description:**

NW10-12  
 78621077084  
 Active

Non-Insulated - High Temperature Ring Terminal For Wire Range 12-10  
 Stud Size #12, Metallic

**WEB\_USE**

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

For easily installed, permanent terminations of solid, round, or stranded nichrome wires as used in toasters, heaters, etc.

**General**

Insulation Type	Non-Insulated - High Temperature
Terminal Series	NW
Material	Nickel Alloy
Finish	Plain
Color	Metallic
Wire Range	12-10
Stud Size	#12

**Dimension Information**

Stock Thickness	.40
A (inches)	.66
B (inches)	.31
C (inches)	.28
M (inches)	.51

**Specifications**

Temperature Rating	1200°F
Voltage Rating	600V

**Tooling**


Tool Charts	Available on Website
Application Tools	WT1377
Recommended Tool	WT1377

**Packaging**

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	250
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.34 lbs. per 100

**Application Support**

Overview	Available on Website
Wire Guide Tables	Available on Website

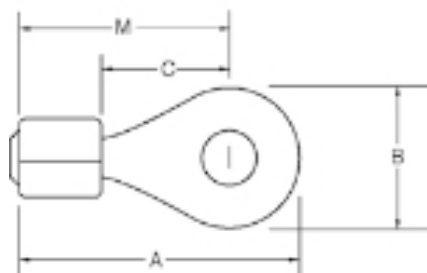

## Notes

Not available on Mylar Tape. #12 stud is smaller than 1/4" stud.

## Certifications

RoHS Compliance	Yes
-----------------	-----

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com