


**LED Undercabinet
LUL9/12/18/24**

Project		Fixture Type
Location		Quantity
Approved By	Date	Catalog Number

Features

All purpose LED undercabinet light with a compact design and low profile. The housing is available in various lengths and includes a high/low switch. The products offer full range dimming when used with an electronic low-voltage dimmer. Accessories include a 5' 3-wire cord and plug, 12" push-in connectors allow for easy hardwire installation. Full size knockouts are located on the top and back. Link up to 50 units for 9", 12" and 18". Link up to 15 units for 24". Maximum run length of 80'. Applications include kitchens, study areas and displays.

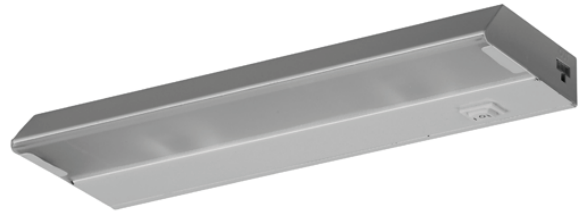

Construction

Housing is die-formed of 22-gauge steel. Separate hingeable service tray allows for easy installation and snaps into position without hardware. Power connections are made inside service tray or with included cord and plug.

Finish

All exposed metal parts are post painted lighting grade white gloss enamel paint or applied oil-rubbed bronze.

Diffuser

Frosted tempered textured glass is .100" thick and slides into housing.

Electrical


This unit is wired for 120V operation. LED driver has a 12VAC output to the LED light engine. High/low switch included. Electronic low voltage dimmers sold separately.

Lamping

LED's are 3,000K non-replaceable and are rated for 50,000 hours.

Certification

Fixtures are cULus listed for dry locations and carry a UL rating for undercabinet/convertible/linkable mounting. ENERGY STAR® qualified with on/off switch, order units with "E" designation.

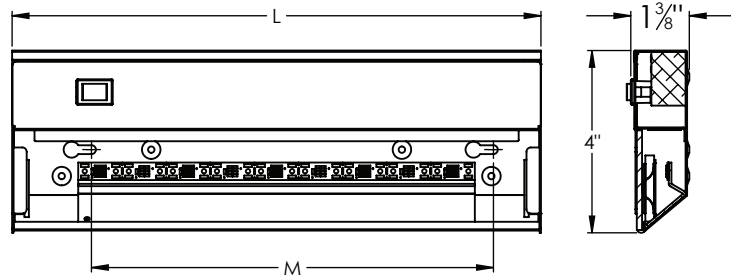

For photometric information, consult factory.

**Specifications and dimensions
subject to change without notice.**

Ordering Information:

Model No.		Finish	Lamps		Lumens	Dimensions			Mounting
120V Hi/Low Switch	120V On/Off Switch		Qty	Type		L	W	D	M
LUL9WH	LUL9EWH	White	3	1W LED	100	9"	4"	1-3/8"	5-7/8"
LUL12WH	LUL12EWH	White	5	1W LED	170	12"	4"	1-3/8"	9-1/8"
LUL18WH	LUL18EWH	White	8	1W LED	270	18"	4"	1-3/8"	15-1/8"
LUL24WH	LUL24EWH	White	11	1W LED	370	24"	4"	1-3/8"	21-1/8"
LUL9RB	LUL9ERB	Oil-Rubbed Bronze	3	1W LED	100	9"	4"	1-3/8"	5-7/8"
LUL12RB	LUL12ERB	Oil-Rubbed Bronze	5	1W LED	170	12"	4"	1-3/8"	9-1/8"
LUL18RB	LUL18ERB	Oil-Rubbed Bronze	8	1W LED	270	18"	4"	1-3/8"	15-1/8"
LUL24RB	LUL24ERB	Oil-Rubbed Bronze	11	1W LED	370	24"	4"	1-3/8"	21-1/8"