
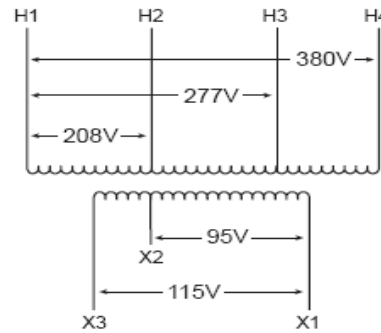
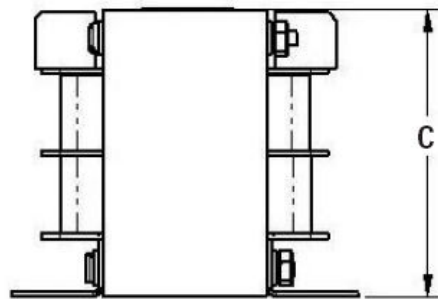


Revisions

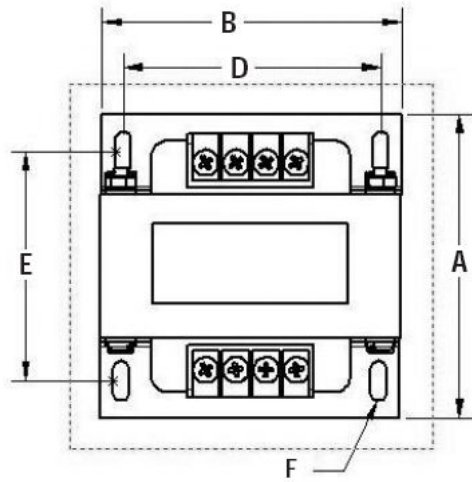

Type No.

VA	CATALOG NUMBER	VOLTAGE		WIRING DIAGRAM	WEIGHT	PHASE	FREQ.
		HIGH	LOW				
150	TB-81304	208/277/380	95/115		5 Lbs	1 ϕ	50/60 Hz

TYPICAL PERFORMANCE DATA

Winding Rise:	80°C
Insulation:	130°C
Windings:	CU

Standards:	UL/CSA	Markings:	
------------	--------	-----------	--

Industrial Control Transformer

Typical Efficiency	
Full Load Losses	
No Load Losses	

A	B	C	D	E	F
5.00	3.75	3.84	3.13	3.06	.22 x .50

A PRINTS TO CONTROL 7