

Low-Profile Strip Lights

T8 Lamps




FEATURES

- Pre-loaded sockets improve the speed of installation and reduce the potential for socket breakage
- The secure fit of the patent-pending channel cover design allows for easy access and quick attachment
- The patent-pending “three point” row aligner locks channel together for straighter, faster row assembly without fasteners
- Compact “gripper back” channel offers structural strength and reduces shipping damage
- Easy “snap n’ lock” end plates allow for quick attachment and exact fit
- Improved “locking track” lamp holder enhances channel strength and lamp stability

ORDERING INFORMATION

Catalog Number	UPC	Description	# of Lamps	Length	Wattage	Voltage	Ballast Type	Lamp Included	Pallet Qty.	Standard Carton Qty.
Z117 MV	745976682675	T8 Low-Profile Strip	1	24"	17	120 - 277	NEMA Premium®, Instant Start	N	448	1
Z125 MV	745976682705	T8 Low-Profile Strip	1	36"	25	120 - 277	NEMA Premium®, Instant Start	N	224	1
Z132 MV	745976682736	T8 Low-Profile Strip	1	48"	32	120 - 277	NEMA Premium®, Instant Start	N	224	1
TZ132 MV	745976682767	Tandem, T8 Low-Profile Strip	2	96"	32	120 - 277	NEMA Premium®, Instant Start	N	224	1
Z217 MV	745976682781	T8 Low-Profile Strip	2	24"	17	120 - 277	NEMA Premium®, Instant Start	N	448	1
Z225 MV	745976682927	T8 Low-Profile Strip	2	36"	25	120 - 277	NEMA Premium®, Instant Start	N	224	1
Z232 MV	745976682941	T8 Low-Profile Strip	2	48"	32	120 - 277	NEMA Premium®, Instant Start	N	224	1
TZ232 MV	745976682989	Tandem, T8 Low-Profile Strip	4	96"	32	120 - 277	NEMA Premium®, Instant Start	N	224	1

DIMENSIONS

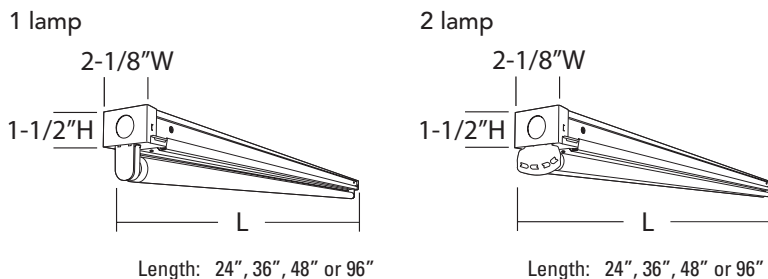

ACCESSORIES

- **Z8ASR48** 48" Asymmetric Reflector, White
- **Z8ASR48 SSR** 48" Asymmetric Reflector, Specular
- **Z8SMR48** 48" Symmetric Reflector, White
- **Z8SMR48 SSR** 48" Symmetric Reflector, Specular
- **WGZ48** 48" Base Wireguard, White
- **ZSPRG M50** Z Spring Hanger (Master Pack of 50)