

Remote Lamps



FEATURES


- Powered by battery equipment as part of an emergency lighting system providing light for the path of egress
- Long lasting, efficient ultra-bright white LED lamp heads
- Fully adjustable lamp heads meet all aiming requirements
- White thermoplastic indoor models
- Die-cast aluminum outdoor models

ORDERING INFORMATION


<i>Catalog Number</i>	<i>UPC</i>	<i>Description</i>	<i>Supply Voltage</i>	<i>Input Wattage</i>	<i>Pallet Qty.</i>	<i>Standard Carton Qty.</i>
ELA LED M12	784231918326	Single, Remote Lamp	9.6	1	192	12
ELA LED T M12	784231918357	Double, Remote Lamp	9.6	2	192	12
ELA LED WP M12	784231918418	Single, Weather-Proof Remote Lamp	9.6	1	192	12
ELA LED T WP M12	784231918449	Double, Weather-Proof Remote Lamp	9.6	2	192	12

DIMENSIONS


ELA LED

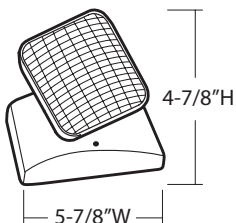

ELA LED T

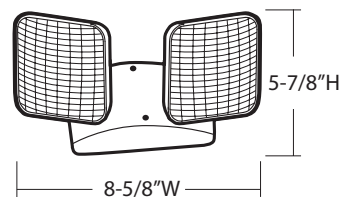

ELA LED WP

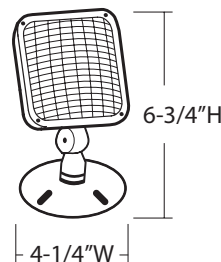

ELA LED T WP

