

FEATURES & SPECIFICATIONS

INTENDED USE

Unique design combines an energy-efficient LED exit sign with an integrated LED emergency light bar, into one low-profile unit.

CONSTRUCTION

Injection-molded, flame-retardant, high-impact, thermoplastic housing with snap-fit design components for easy installation. Universal J-box pattern. Universal chevrons are easily removed for directional indication. Fully assembled single face with extra faceplate for easy field-conversion to double face. Integrated LED emergency light bar swivels to allow for full range of light adjustment.

Letters 6" high with 3/4" stroke, with 100 ft viewing distance rating, based on UL924 standards.

OPTICS

White LEDs are in series providing redundant light sources to ensure emergency lighting performance. The typical life of the exit LED lamp is 10 years. 1.5W per face.

ELECTRICAL

Dual-voltage input 120V or 277V AC; 9.6V output. Emergency combo provided with test switch, status indicator and rechargeable battery. Maintenance-free nickel cadmium high-output battery standard provides 90 minutes of emergency power and powers up to 2 LED remote lamps.

LISTINGS

UL Listed. Meets UL 924, NFPA 101, NFPA 70-NEC and OSHA illumination standards. Indoor damp location 0°C to 50°C (32°F to 122 °F) listed standard.

WARRANTY

Fixtures are covered by Lithonia Lighting 24-month warranty against mechanical defects in manufacture.

All life safety equipment, including emergency lighting for path of egress must be maintained, serviced, and tested in accordance with all National Fire Protection Association (NFPA) and local codes. Failure to perform the required maintenance, service, or testing could jeopardize the safety of occupants and will void all warranties.


Actual performance may differ as a result of end-user environment and application.

Note: Specifications subject to change without notice.

Catalog Number
Notes
Type

Contractor Select

Integrated Exit/Unit Combos

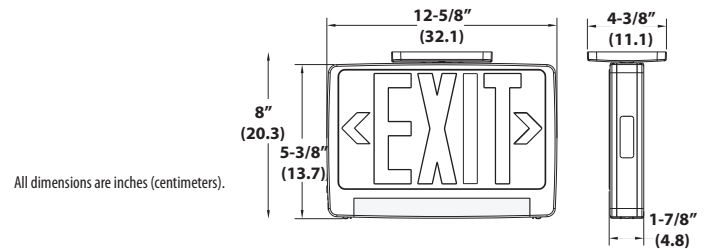

ORDERING INFORMATION

Catalog Number	UPC	Description	Supply Voltage	Input Wattage	Pallet Qty.	Standard Carton Qty.
ECBR LED M6	784231874912	Red, integrated LED light bar	120/277	3.0	360	6
ECBG LED M6	784231874943	Green, integrated LED light bar	120/277	3.0	360	6

Accessories: Order as separate catalog number.

ELA WG1	Back mount wireguard ¹
ELA LED M12	Single remote lamp ²
ELA LED T M12	Double remote lamp ²
ELA LED WP M12	Single, weather-proof remote lamp ²
ELA LED T WP M12	Double, weather-proof remote lamp ²

Notes

- See spec sheet [ELA-WG](#).
- See spec sheet [LED-Remote Lamps](#).

