

FEATURES & SPECIFICATIONS

INTENDED USE — Recessed housing rated IC or Non-IC. For remodel construction only.

Approved for factory assembled wiring only.

Approved for direct burial in insulation.

CONSTRUCTION — Air-tight standard. Tested to meet current energy codes.

Aluminum housing with three remodel clips for installation in existing plaster, sheet rock or mechanical ceiling.

Heavy-gauge galvanized steel raceway arm.

Galvanized steel junction box with four built-in Romex clamps. Five 1/2" knockouts with slots for pryout. Not suitable for pulling wires.

Rated for 90° C.

Ground wire provided.

Removable J-box doors for easy access.

ELECTRICAL — Durable medium base porcelain socket with nickel-plated copper alloy screw shell and contact.

Socket clips to top of housing to prevent paint overspray in socket screw shell.

Socket attaches to reflector to ensure proper and consistent lamp position.

Thermal protection provided against improper lamp usage.

120 volt only.

INSTALLATION — Air-tight housing suitable for air-tight installations. Refer to energy codes for proper installations.

2x8 and 2x6 existing ceiling or T-bar ceiling panel installation.

Clip adjustment on housing (up to 1/2") allows for flush mounting with ceiling face.

LISTINGS — UL Listed to US and Canadian safety standards. Damp location listing (See trim selection for wet location listing).

WARRANTY — 1-year limited warranty. Complete warranty terms located at

www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Specifications subject to change without notice.

Catalog Number
Notes
Type


4" Remodel Housing

L3R

INCANDESCENT

IC/Non-IC

Remodel Construction

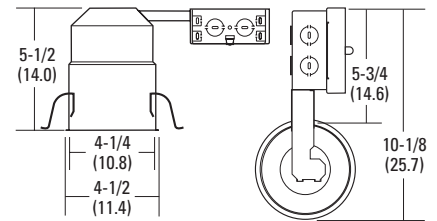

Specifications

Height: 5-1/2 (14.0)

Length: 10-1/8 (25.7)

Width: 4-1/2 (11.4)

Ceiling opening: 4-1/4 (10.8)

Ceiling cutout template: 4.01

All dimensions are inches (centimeters) unless otherwise specified.

ORDERING INFORMATION

For shortest lead times, configure product using **bolded options**.

Example: L3R R6

L3R	Options	Packaging
L3R	Shipped installed in fixture PHC Poke-home wire connector	R6 Resale pack of six U Unit

Accessories: Order as separate catalog number.
ATK3 R6 Airtight trim kit

Notes

See trim summary on reverse side for maximum wattages.

L3R 4" Remodel Housing

Description Catalog number	Maximum wattage ¹	Description Catalog number	Maximum wattage ¹	Description Catalog number	Maximum wattage ¹	Description Catalog number	Maximum wattage ¹								
General/Task				Accent/Wallwash											
Open Narrow Flange 301 White 301MW Matte white 301A Clear diffuse, white plastic flange 301A PFMW Clear diffuse, matte white plastic flange 301AZ Clear specular anodized 301BLZ Black specular anodized 301BN Brushed nickel 301BZA Antique bronze 301ORB Oil-rubbed bronze Baffle Narrow Flange 3B1W White 3B1MW Matte white				Baffle Narrow Flange 3B1 Black 3B1 TRMW Black matte, white flange 3B1BN Brushed nickel 3B1BZA Antique bronze 3B1ORB Oil-rubbed bronze Baffle Deep Narrow Flange 3B2 Black Baffle Deep Narrow Flange 3B2W White				Eyeball Narrow Flange 3E1 White 3E1MW Matte white 3E1BN Brushed nickel 3E1BZA Antique bronze 3E1ORB Oil-rubbed bronze Wallwash Narrow Flange 3W1 White Pinhole Narrow Flange 3S1 White				Wet Location² Wetlite Narrow Flange 3H20 White 3H20MW Matte white 3H20BN Brushed nickel 3H20BZA Antique bronze 3H20ORB Oil-rubbed bronze			
IC	30 R20 35 PAR20	IC	35 PAR20	IC	50 PAR20 50 R20	IC	75 PAR30 Short neck								
Non IC	50 PAR20	Non IC	50 PAR20 50 R20	Non IC	50 R20 50 PAR20										
IC	50 PAR20 50 R20	IC	30 R20 35 PAR20	IC	35 PAR20										
Non IC		Non IC	50 R20	Non IC	50 PAR20										

Notes

- 1 Maximum wattage listed. Lower wattage lamps may be used.
- 2 Wetlite trim is wet location listed and outdoor rated. All other trims are damp location.

P Series Baffle Wide flange (Wet location)



Example: 4BPMW LED

ORDERING INFORMATION For shortest lead times, configure product using **bolded options**.

4BPMW		LED		
Series/Finish		Lamp/Lumen ¹	Color temperature	Voltage
Series 4BP 4" Baffle LED module	Finish MW Matte white	LED 620 lumens, 10.6 watts	(blank) 3000K	(blank) 120V

LED Gimbal (Damp location)



Example: 4G1MW LED

ORDERING INFORMATION For shortest lead times, configure product using **bolded options**.

4G1		LED		
Series/Finish		Lamp/Lumen ¹	Color temperature	Voltage
Series 4G1 4" Gimbal module	Finish MW Matte white MB Matte black BN Brush nickel ORB Oil-rubbed bronze	LED 435 lumens, 7.9 watts	(blank) 3000K	(blank) 120V

Notes

- 1 Total system delivered lumens.
- 2 L3R must be ordered on separate line.