


# LPJ

**Non-IC-Rated Full Reflectors** – All reflectors are damp location listed. Lensed reflectors are wet location listed. Lamp types and maximum wattages are listed for each reflector. Maximum ceiling thickness 1/2". Consult factory for thicker ceiling applications.


**Open reflector**

**J01** White  
Other finishes: A/G

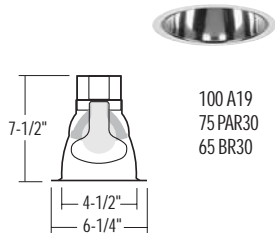



**Open cone**

**JC1**  
Other finishes: A/G/BL

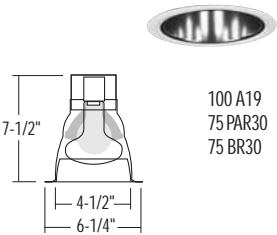

**Premium metal baffle**

**JB1** White reflector/  
black baffle  
Other finishes: W

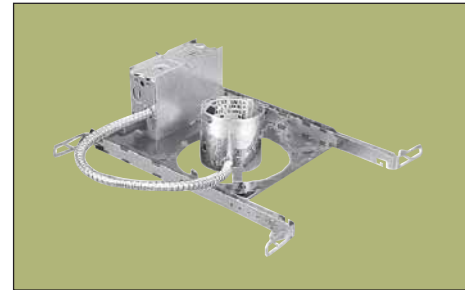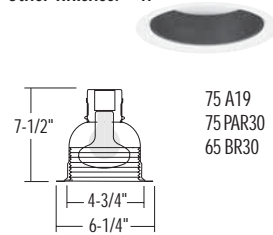

**Intended Use**

New construction applications requiring high performance vertical reflectors using incandescent lamps.

**Features**

**Mechanical** – Rugged, galvanized steel frame-in with trim retaining clips to secure optical system. Galvanized bar hangers span up to 24" o.c. and feature built-in nailers and T-bar clips. Galvanized steel junction box with removable access door, (4) Romex knockouts, (2) 3/4" and (4) 1/2" nominal conduit knockouts with pryout slots.


**Electrical System** – Durable medium-base porcelain socket with nickel-plated copper alloy screw shell and contact. Maximum 8 (4 in, 4 out) No. 12 AWG conductor. Rated for 90°C supply wire. Ground wire provided. Class P thermally protected ballast protects against improper contact with insulation and approved for through-branch circuit wiring.

**Listings**

UL Listed to U.S. and Canadian safety standards.


**Baffle**

**JB4** White Reflector/  
black baffle  
Other finishes: W/C/G

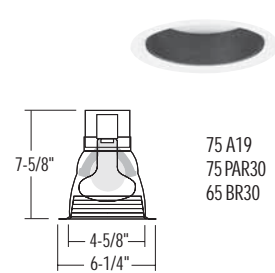

**Baffle eyeball**

**JE1** White sphere and  
flange w/black  
baffle  
Other finishes: W

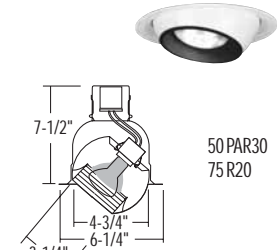

**Ordering Information**

Example: **LPJ J01**

Series	Reflector	Options
LPJ	<p><b>J01</b> White open</p> <p><b>J01A</b> Clear specular open</p> <p><b>J01G</b> Gold specular open</p> <p><b>JC1A</b> Clear specular cone</p> <p><b>JC1G</b> Gold specular cone</p> <p><b>JC1BL</b> Black specular cone</p> <p><b>JB1</b> White reflector/black baffle</p> <p><b>JB1W</b> White reflector/white baffle</p> <p><b>JB4</b> White reflector/black baffle</p>	<p><b>JB4W</b> White reflector/white baffle</p> <p><b>JB4C</b> White reflector/chrome baffle</p> <p><b>JB4G</b> White reflector/gold baffle</p> <p><b>JE1</b> White sphere and flange w/black baffle</p> <p><b>JE1W</b> White sphere and flange w/white baffle</p> <p><b>SDT</b> 277V stepdown transformer (277V to 120V).</p> <p><b>TRW</b> White flange.</p>

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches.

**STANDARD PACKAGING**  
To order, use single master catalog number.  
Example: (13) LPJJ01  
**Fixtures ship** as multiple components using optimized packaging. Example above ships as:  
(Qty 12) LPJJ6 (2 cartons of 6 housings)  
(Qty 1) LPJLU (1 carton of 1 housing)  
(Qty 13) J01 (13 cartons of 1 reflector)

