



Catalog Number	
Notes	Type


Indoor Decorative

Low Profile Round Flush Mount

Circline T9 or Compact DTT Fluorescent



* Only fixtures that include lamps are ENERGY STAR® certified.

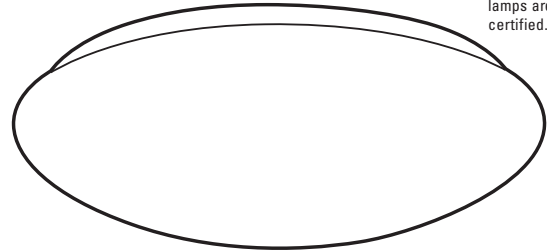

FEATURES & SPECIFICATIONS

INTENDED USE

Provides general illumination in residential applications. **If required for commercial application or operation more than eight (8) hours per day, consult factory for available options.** Ideal for use in foyers, hallways, bedrooms, offices, utility work areas, stairways and many other rooms in the house.

ATTRIBUTES

The beauty of simplicity in low profile styled, round, stay-white, acrylic diffuser, available in four sizes: 11", 14", 19" or 24". These fixtures provide an attractive low-cost lighting solution for every room in the home. Hidden cam-latches provide easy diffuser removal for installation and maintenance.

Fixtures available with lamps and without lamps. Fixtures without lamps are available in either compact double twin tube (DTT) 4-pin or circline T9 fluorescent lamp(s) configurations. Fixtures with lamps include circline T9 4100K fluorescent lamp(s) for energy efficiency, superior color rendering long life.

Standard with electronic ballast (120 volt, 60Hz) ensures no flickering and quiet operation without interfering with other home electronics. For use with non-dimmable switches only.

All mounting hardware included.

LISTING

CUL listed to US and Canadian safety standards and suitable for damp locations. Fixtures with lamps are ENERGY STAR® certified.

WARRANTY


Guaranteed for two years against mechanical defects in manufacture. (excludes lamps)

DIMENSIONS

Nominal Size	Lamp Configuration	Model Number	Number of Lamps	(A) Width inches (cm)	(B) Extension* inches (cm)
11" dia		FM22 ACLR LP	(1) 22W circline T9	11" (27.9)	3-1/4" (8.3)
		FMLR22	(1) 22W circline T9	11" (27.9)	3-1/4" (8.3)
		FMLR11 2 13 DTT	(2) 13W compact DTT	11" (27.9)	3-1/4" (8.3)
14" dia		FM54 ACLR LP	(1) 22W & (1) 32W circline T9	13-3/4" (34.8)	3-1/2" (8.9)
		FMLR54	(1) 22W & (1) 32W circline T9	13-3/4" (34.8)	3-1/2" (8.9)
		FMLR14 2 18 DTT	(2) 18W compact DTT	13-3/4" (34.8)	3-1/2" (8.9)
19" dia		FM72 ACLR LP	(1) 32W & (1) 40W circline T9	19-1/4" (47)	3-5/8" (9.2)
		FMLR72	(1) 32W & (1) 40W circline T9	19-1/4" (47)	3-5/8" (9.2)
		FMLR19 3 26 DTT	(3) 26W DTT	19-1/4" (47)	3-5/8" (9.2)
24" dia.		FMXLR 72	(1) 32W & (1) 40W circline T9	24" (61)	4-3/4" (12)

* Extension from ceiling

All dimensions are in inches (centimeters)

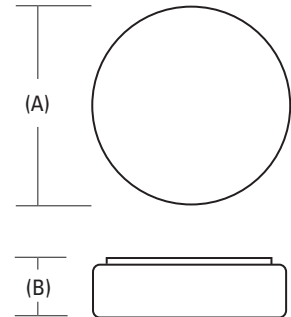

ORDERING INFORMATION

Example: **FM22 ACLR LP**

Choose the boldface catalog nomenclature that best suits your needs and write it on the appropriate line. Order accessories and replacement parts as separate catalog numbers.

Model Number¹	
---------------------------------	--

Options	
----------------	--

(Consult factory)

11" diameter

FM22 ACLR LP

(1) 22W circline T9 lamp **Included²**

FMLR 22

(1) 22W circline T9 lamp **Required³**

FMLR11 2 13 DTT

(2) 13W compact (DTT) lamp(s) **Required**

14" diameter

FM54 ACLR LP

(1) 22W & (1) 32W circline T9 lamp(s) **Included²**

FMLR 54

(1) 22W & (1) 32W circline T9 lamp **Required³**

FMLR14 2 18 DTT

(2) 18W compact (DTT) lamp(s) required **Required³**

19" diameter

FM72 ACLR LP

(1) 32W & (1) 40W circline T9 lamp(s) **Included²**

FMLR 72

(1) 32W & (1) 40W circline T9 lamp **Required³**

FMLR19 3 26 DTT

(3) 26W compact (DTT) lamp(s) required **Required³**

24" diameter

FMLXR

(1) 32W & (1) 40W circline T9 lamps **Included²**

Notes:

1. Use with non-dimmable switches only.
2. **INCLUDES** - circline T9 4100K fluorescent lamp(s)
3. **Lamp(s) not included. Not ENERGY STAR qualified.**