

FEATURES & SPECIFICATIONS

INTENDED USE

For use with housings LCP, LC6, L7XP, L7XPR, L7X, L7XR, L7XF and L7XFR.

CONSTRUCTION

Aluminum one-piece reflector.

White polyester powder coat paint.

Antique bronze, oil-rubbed bronze, brushed nickel and white finishes are one piece aluminum with integral flange.

INSTALLATION

Socket to trim interface.

Trim retention is achieved by utilizing two side-mounted torsion springs on the trim and two receiving brackets in the can, ensuring a consistently tight fit with the ceiling.

LISTINGS

UL Listed to US and Canadian safety standards.

Damp location listed.

WARRANTY

1-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Actual performance may differ as a result of end-user environment and application.

Note: Specifications subject to change without notice.

Catalog Number
Notes
Type

6" Finishing Trim

C01

OPEN SHALLOW
Wide Flange



Oil-rubbed bronze



Brushed nickel



Antique bronze


Specifications

Height: 5-7/8 (14.9)

Lamp opening: 4-1/4 (10.8)

Diameter: 7-3/4 (19.7)

All dimensions are inches (centimeters) unless otherwise indicated.

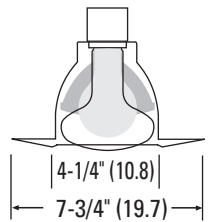

ORDERING INFORMATION

For shortest lead times, configure product using **bolded options**.

Example: C01-TOR

C01		TOR
Series	Finish	Mounting method
C01	(blank) White BN Brushed nickel ORB Oil-rubbed bronze BZA Antique bonze	TOR Torsion springs

Housing Compatibility: Housing and trim ordered separately.

Application	Source	Maximum wattage	Housing
IC	Incandescent	75 PAR30 short neck	LCP, LC6, L7XP, L7XPR, L7X, L7XR
		65 BR30	
		60 A19	
	Fluorescent	13DTT	L7XF, L7XFR

