

## FEATURES & SPECIFICATIONS

### INTENDED USE

Single and twin LED remote lamps for indoor and outdoor applications, for use as part of an emergency lighting system, providing light for path of egress.

### CONSTRUCTION

Indoor remote heads are injection-molded, engineering-grade, 5VA flame retardant, high-impact resistant, thermoplastic, white finish.

Weather-proof (WP) are die-cast aluminum, sealed and gasketed, gray finish. For use in damp and wet location areas.

Only compatible with EC LED HO, ECB LED, LHQM LED HO.

Fully adjustable lamp heads.

Suitable for wall or ceiling mount. Mounts to a single-gang switch box.

### OPTICS

One watt per head. The typical life of the LED lamp is 10 years. To be powered from low-voltage power source (9.6V only).

### LISTINGS

UL Listed.

Damp location listed (ELA LED) 32°F to 122°F (0°C to 50°C).

Wet location listed (ELA LED WP) -4°F to 122°F (-20°C to 50°C)

### WARRANTY

2-year limited warranty. Complete warranty terms located at:

[www.acuitybrands.com/CustomerResources/Terms\\_and\\_conditions.aspx](http://www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx).

All life safety equipment, including emergency lighting for path of egress must be maintained, serviced, and tested in accordance with all National Fire Protection Association (NFPA) and local codes. Failure to perform the required maintenance, service, or testing could jeopardize the safety of occupants and will void all warranties.

NOTE: Actual performance may differ as a result of end-user environment and application.

All values are design or typical values, measured under laboratory conditions at 25°C.

Specifications subject to change without notice.

Catalog Number
Notes
Type

Contractor Select

# LED Remote Lamps

LED Lamps



ELA LED



ELA LED T




ELA LED WP




ELA LED T WP


ELA LED

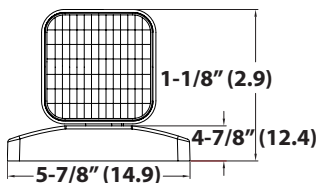


ELA LED T

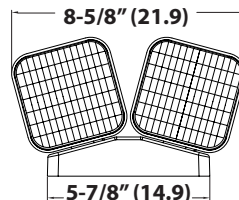

ELA LED WP

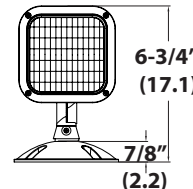

ELA LED T WP

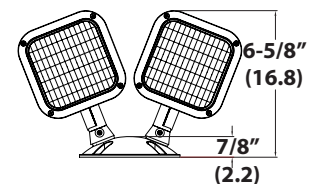

All dimensions are inches (centimeters).

Shipping weight: 3.6 lbs. (1.6 kgs.).

### ORDERING INFORMATION

Catalog Number	UPC	Description	Voltage	Wattage <sup>1</sup>	Pallet Qty.	Standard Carton Qty.
ELA LED M12 <sup>2</sup>	784231918326	Single remote lamp	9.6	1	432	12
ELA LED T M12 <sup>2</sup>	784231918357	Double remote lamp	9.6	1	288	12
ELA LED WP M12 <sup>2</sup>	784231918418	Single, weather-proof remote lamp	9.6	1	432	12
ELA LED T WP M12 <sup>2</sup>	784231918449	Double, weather-proof remote lamp	9.6	1	192	12

#### Notes

1 Per lamp head

2 Only compatible with [EC LED HO](#), [ECB LED](#), [LHQM LED HO](#).