

FPM-3171G

8U Rackmount 17" SXGA Industrial Monitor with Resistive Touchscreen, Direct-VGA and DVI Ports, and Wide Operating Temperature Range



Features

- 17" SXGA TFT LED LCD with 50,000 hours of backlight life
- Robust design with stainless steel chassis and aluminum front panel
- Anti-glare screen with tempered glass and IP65 certified front panel
- Lockable OSD control pad on rear cover
- Supports industrial 24V_{DC} power input
- Supports panel, wall, desktop, rack or VESA arm mounting
- Supports 8U pre-drill Rackmount mounting hole

Introduction

FPM-3171G is a 17" color TFT LCD flat panel monitor specifically designed for industrial applications. With a viewing size as large as 17", it presents a simple display area as well as vivid and sharp images for your HMI. It features direct VGA signal transmission. You can thus upgrade the displays without making changes to the existing system. The onscreen display function also makes it easy to adjust the images on the screen. The whole chassis is designed in stainless steel and the front panel is made of aluminum with front panel IP65 compliance.

Specifications

General

- **Button Controls** OSD (Onscreen Display) control pad on front panel
- **Certification** BSMI, CCC, CE, FCC Class A, UL
- **Dimensions (W x H x D)** 482 x 354.8 x 63.5 mm (18.98" x 13.97" x 2.52")
- **Enclosure** Front panel: Aluminum with coating
Rear cover: Stainless steel chassis
- **Mounting** Panel, wall, desktop, VESA arm & 19" rackmount
- **Power Input** Phoenix Jack: 24 V_{DC} input
DC Jack: 12 V_{DC} Input
- **Power Consumption** 23W +20%
- **Video Port** VGA & DVI-D port
- **Weight (Net)** 9.25 kg (20.39 lbs)

LCD Display

- **Display Type** 'SXGA TFT LCD with LED backlight
- **Display Size** 17"
- **Max. Resolution** 1280 x 1024
- **Max. Color** 16.7 M
- **Viewing Angle (H/V°)** 160/140
- **Luminance (cd/m²)** 350
- **Backlight Life (hrs)** 50,000
- **Contrast Ratio** 1000:1

Touchscreen

- **Driver** Penmount 6000
- **Interface** RS-232 and USB
- **Lifespan** 35 million touches at a single point
- **Light Transmission** > 80%
- **OS Support** Windows XP, 2000, Vista, 7, 8/8.1, 10, XP/7/8/10 Embedded, CE, Linux
- **Power Consumption** +5 V @ 100 mA
- **Touch Resolution** Linearity


Environment

- **Operation Temperature** -20 ~ 60°C (-4 ~ 140°F)
- **Storage Temperature** -30 ~ 80°C (-22 ~ 176°F)
- **Humidity (Storage)** 90% @ 50°C non-condensing
- **Waterproof** Front panel is IP65 compliant
- **Vibration** 5 ~ 500 Hz, 1 Grms (Operating, Random)

Dimensions

Unit: mm [inch]

Diameters of the rackmount holes:
Vertical: 6.5 mm
Horizontal: 9 mm

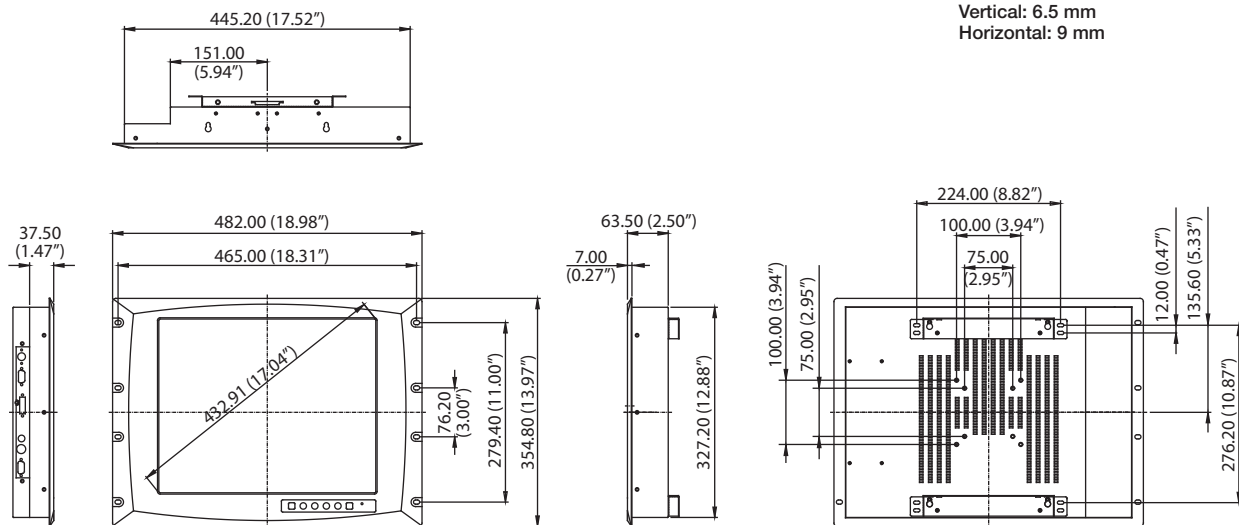

Panel Cut-out Dimensions: FPM-3171G: 447.2 x 329.2 mm (17.6" x 12.96")

Ordering Information

- FPM-3171G-R3BE 17"SVGA WT Ind. Monitor w/Resistive TS (Combo)

Optional Accessories

- 1702002600 Power Cable US Plug 1.8 M
- 1702002605 Power Cable EU Plug 1.8 M
- 1702031801 Power Cable UK Plug 1.8 M
- 1700000596 Power Cable China/Australia Plug 1.8 M (Direct rack mounting, no need accessory)
- 96PSA-A60W12V1-1 Adapter 100-240V 60W 12V 5A
- 96PSA-A60W24T2 Adapter 100-240V 60W 24V 2.5A
- FPM-3001G-ADKE Adapter bracket for FPM-3000 15"/17"/19"

I/O View

