


ALL200RM SPEC SHEET

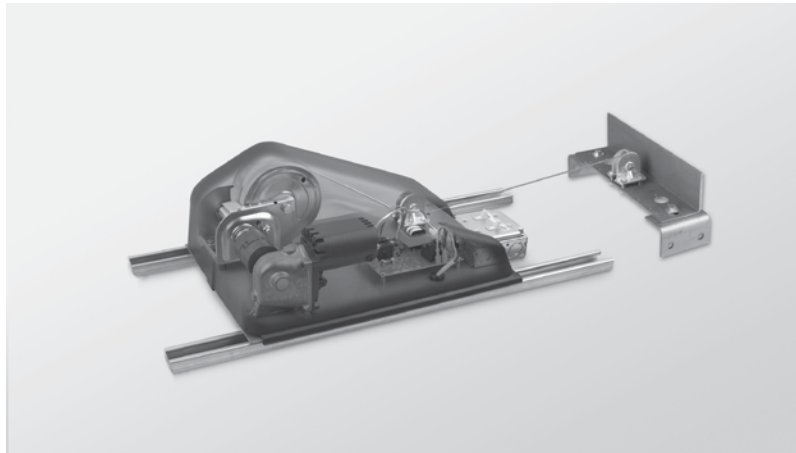

This spec sheet is for the ALL200RM. This light lift is for installations where there is not three feet of vertical access space directly above the chandelier. If there is adequate and accessible space above the chandelier, please see STANDARD MOUNT LIGHT LIFTS on page 1.

Maximum Lifting Capacity.....	200 lbs.
Winch Cable Length.....	65 ft. (standard) 90 ft. (optional) 120 ft. (optional)
Light Wattage Capacity.....	1 circuit - 1650 watts (standard) 1 circuit - 2200 watts (optional)
Motor and Light Voltage Requirements.....	110V
Mounting Location.....	Up to 25 ft. away from ceiling box location
Controller.....	Keyswitch (standard) SmartLift (optional)
Dimensions of Unit.....	14" wide x 19" long x 9" high Mounted on two 36" channel struts
Shipping Weight.....	Varies, call factory
Shipping Method.....	FedEx only

