


# ALL200 SPEC SHEET

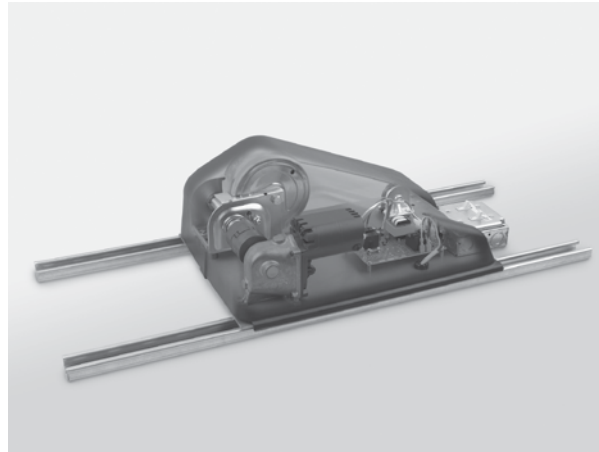

This spec sheet is for an ALL200 that mounts in an accessible location directly above the chandelier. If there is not three feet of vertical access space directly above the chandelier, please see the REMOTE MOUNT LIGHT LIFTS on page 6.

Maximum Lifting Capacity.....	200 lbs.
Winch Cable Length.....	35 ft. (standard) 65 ft. (optional) 90 ft. (optional)
Light Wattage Capacity.....	1 circuit - 1650 watts (standard) 1 circuit - 2200 watts (optional) 2 circuit - 3300 watts (optional)
Motor and Light Voltage Requirements.....	110V
Mounting Location.....	Directly above chandelier only 3 ft. vertical access space minimum
Controller.....	Keyswitch (standard) SmartLift (optional)
Dimensions of unit.....	14" wide x 19" long x 9" high Mounted on two 36" channel struts
Shipping Weight.....	47 lbs.
Shipping Method.....	FedEx only

