


# IEC Load Switches, 16...100 A

## Product Selection/Catalog Number Explanation

### Bulletin 194E Enclosed Disconnect Load Switches with 194R Handles (with Defeater, suitable for 3 padlocks)

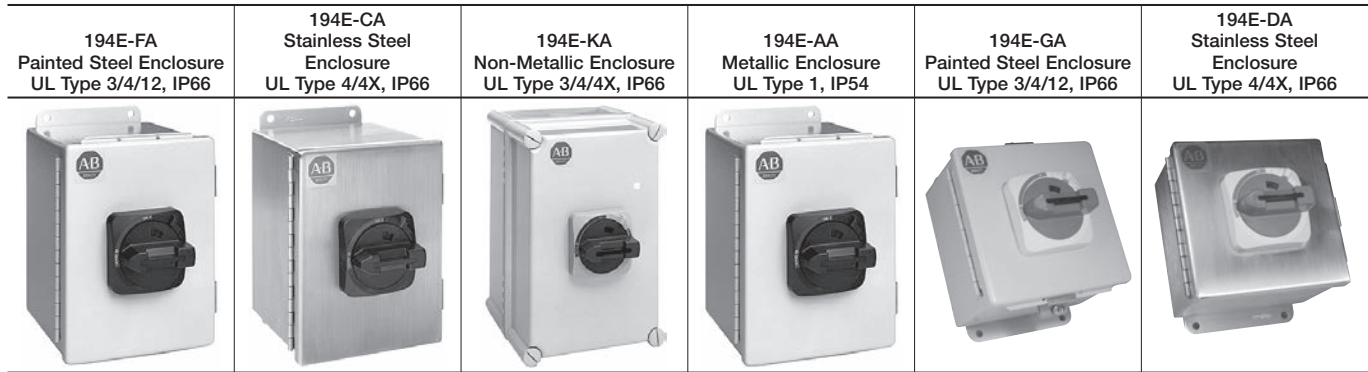

2

Cat. No. Explanation \*§

**194E - FA 32 E - P11 - P11 - 6**  
*a b c d d e*

<i>a</i>	
Code	Enclosure Type
FA	UL Type 3/4/12, IP66 Painted Steel, Hinged, for 16...100 A switches
GA	UL Type 3/4/12, IP66 Painted Steel, Hinged, in 6 x 6 x 4 in. size, for 16...32 A 3-pole switches ‡
CA	UL Type 4/4X, IP66 Stainless Steel, Hinged, for 16...100 A switches
DA	UL Type 4/4X, IP66 Stainless Steel, Hinged, in 6 x 6 x 4 in. size, for 16...32 A 3-pole switches ‡
KA	UL Type 3/4/4X, IP66 Non-Metallic, for 16...100 A switches
AA	UL Type 1, IP54 Painted Steel, Hinged, for 16...100 A switches (Same enclosure as FA without gasketing)

<i>b</i>	
Code	Load Size
16	16 A
20	25 A
32	32 A
40	40 A
63	63 A
80	80 A
00	100 A

<i>c</i>	
Code	Handle Color (194R-HS _ _)
Blank	Grey/Black
E	Red/Yellow

<i>d</i>	
Code	Left Side + Right Side Modifications*
Blank	No Option
-P11	1 N.O. + 1 N.C. Auxiliary Contacts
-PL11	1 N.O. + 1 N.C.L.B. Auxiliary Contacts
-P22	2 N.O. + 2 N.C. Auxiliary Contacts
-PD10	1 N.O. E.B.
-NP	Additional Pole
-PE	Grounding Pole
-TN	Neutral Pole

<i>e</i>	
Code	Switch Type
Blank	3-pole switch
-6	6 Pole switch§

- \* Modifications: Up to two suffix codes may be added to an enclosed disconnect load switch. See Guidelines, page 2-409. If only one accessory is chosen, it is mounted on the left side of the switch.
- § To order the cat. no. 194E-FA40/FA63 or 194E-CA40/CA63 in the larger 80/100A sized enclosure, add an "X" after the handle color. For example, Cat. No. **194E-FA40E** becomes Cat. No. **194E-FA40EX**.
- ‡ GA and DA type enclosures: use with 3-pole 16...32 A switches only.
- § Special order; allow for longer delivery time.

### Frequently Ordered Bulletin 194E Enclosed Switches with Bulletin 194R Handle

Description	Rated Current (A)	Dimension Reference	Handle Color	Cat. No.*
Stainless steel enclosure, IP66/Type 4/4X	25	A1	Black	194E-CA20
			Red/Yellow	194E-CA20E
	32	A1	Black	194E-CA32
			Red/Yellow	194E-CA32E
	63	A1	Black	194E-CA63
			Red/Yellow	194E-CA63E
Painted steel enclosure, IP66/Type 3/4/12	25	A1	Black	194E-FA20
			Red/Yellow	194E-FA20E
	32	A1	Black	194E-FA32
			Red/Yellow	194E-FA32E
	40	A1	Black	<b>194E-FA40</b>
			Red/Yellow	194E-FA40E
Non-metallic enclosure, IP66/Type 4/4X	25	C1	Black	194E-KA20
			Red/Yellow	194E-KA20E

\* Modifications: Up to two suffix codes may be added to an enclosed disconnect load switch. See Guidelines, page 2-409. If only one accessory is chosen, it is mounted on the left side of the switch.