 





Environmentally-Sealed Connectors help protect against harsh industrial environments. An environmental boot with Stainless Steel locking ring ensures a solid connection. The Teflon jacketed cable and higher temperature boot permit operation up to 350 Degrees F. The 2-socket version fits standard MIL-C-5015 style connectors.

 



2-Conductor	-58 to 392	0.19"	27
Twisted, Shielded Pair	Degrees F	OD	pf/ft
Orange Teflon Jacket			

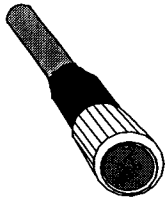

**2-Socket Premium Splash Proof
Connector with Stainless Steel
Locking Ring
-50 to 250 Deg F**

<u>Part Number</u>	<u>Description</u>
46800I	Splash Proof Cable Assembly, 16ft; 2-Socket Connector
46801I	Splash Proof Cable Assembly, 32ft; 2-Socket Connector
46802I	Splash Proof Cable Assembly, 64ft; 2-Socket Connector
46806I	Splash Proof Cable Assembly, 112ft; 2-Socket Connector

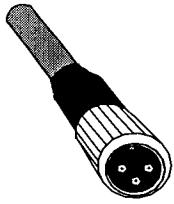

**3-Socket Premium Splash Proof
Connector with Stainless Steel
Locking Ring**

-50 to 250 Deg F

<u>Part Number</u>	<u>Description</u>
46803I	Splash Proof Cable Assembly, 16ft; 3-Socket Connector
46804I	Splash Proof Cable Assembly, 32ft; 3-Socket Connector
46805I	Splash Proof Cable Assembly, 64ft; 3-Socket Connector

Installation Diagram:

