

INCANDESCENT ROPE KITS

Convenient, interconnectable and economical kits

INCANDESCENT ROPE KITS

Easy to use kits in six different lengths! Combine kits for accent lighting or outlining projects such as railings, steps, coves, patios, gazebos, displays, shelving, built-ins, toe kicks and more.

FEATURES


- Indoor/outdoor rated
- Dimmable
- Rope Light Kits include: UL2388 Listed or CSA Rated Rope Light, pre-connected (removable) five foot power cord, removable end cap and one mounting clip per foot
- Kits are easily extendable up to 150 feet (CSA) or 200 feet (UL) for premium grade; up to 150 feet for commercial grade
- Quickly attach multiple kits together without the use of tools
- Highest quality PVC with UV inhibitor to maximize life




Commercial Grade



Premium Grade

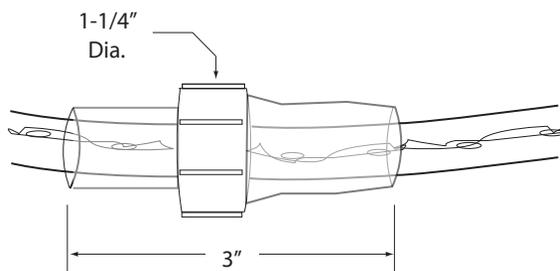

Interconnection of two kits

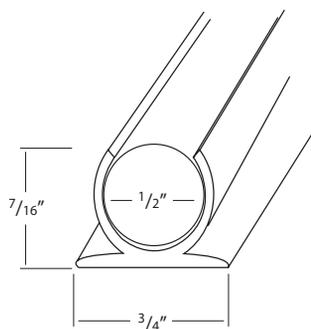


BILL OF MATERIALS

- Determine length needed to the nearest 24" increment
- Order kits in lengths to match target length, up to maximum run lengths as indicated on facing page
- Order mounting track for straight runs (recommended); clips are included with kits (one per foot of rope)

Bill of Materials for example below:

(6) 042-CL-10

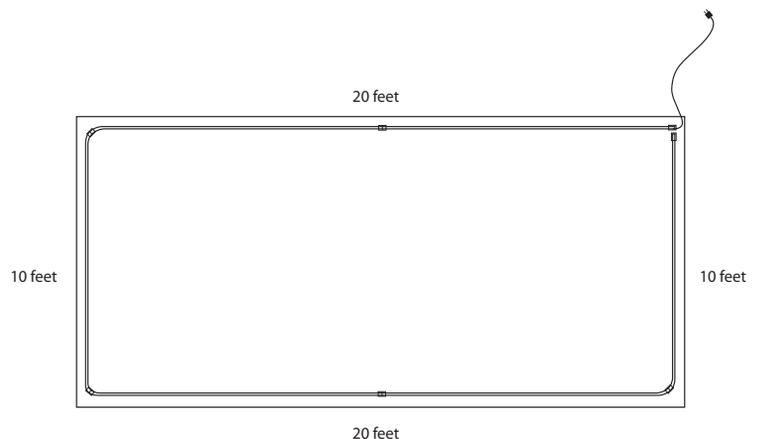

Consider using shorter length kits to build longer custom lengths. If one section should fail, a kit can be replaced (which maintains UL Listing) versus repairing a section, which voids UL.

UL KITS

042-CL	—	[]
Commercial Grade, UL Listed		2 = 2' kits, 10 per case 6 = 6' kits, 10 per case 10 = 10' kits, 10 per case 18 = 18' kits, 5 per case 30 = 30' kits, 5 per case 50 = 50' kits, 4 per case
		

CSA KITS

CSA-CL	—	[]
Premium Grade, CSA Rated		2 = 2' kits, 10 per case 6 = 6' kits, 10 per case 10 = 10' kits, 10 per case 18 = 18' kits, 5 per case 30 = 30' kits, 5 per case 50 = 50' kits, 4 per case
		

ACCESSORIES



ULRL-EXT-3

Three foot jumper for Rope Light Kits, white wire; includes two power connectors, blister pack



RL-TRK-3

Three foot clear mounting track
Sold in case quantities of 40 only!



DL-CLIP/SCREW

Clear "U" shaped mounting clip that securely holds rope light in place



DL-TRACK-4

Four foot clear mounting track with UV rating for outdoors; recommended for use with straight line installations

TECHNICAL SPECIFICATIONS

Voltage	120V, 60Hz AC operation
Construction	UV resistant clear PVC housing with incandescent lamps spaced every 1.09" for 042 kits and 1" spacing for 018 and CSA-CL kits, vertical mount
Mounting	Clear plastic mounting clips or track
Dimensions	1/2" diameter
Light output	042 kits = 6.5 lumens per foot, 018 and CSA-CL kits = 4.6 lumens per foot
Wattage	042 kits = 3.78 watts per foot; 018 and CSA-CL kits = 3.1 watts per foot
Maximum run	150 feet for 042 and CSA-CL kits; 200 feet for 018 kits
Switching	Provide switched outlet for On/Off and dimming control
Linking	Interconnect kits with no additional parts or use ULRL-EXT-3 jumper for connecting two sections together
Lamp specs	25,000 hour rated life; 6.5V, 70mA, 1.09" lamp spacing for 042 kits; 5V, 50mA, 1" lamp spacing for 018 and CSA-CL kits
Dimmers	Switched wall outlets cannot be used with wall dimmers per the NEC. Dimmable with most standard incandescent dimmers.
Diffuser	Clear PVC jacket
Packaging	042 kits packaged in white boxes; 018 and CSA-CL kits packaged in retail blister packs (2', 6' and 10' lengths) or retail boxes (18', 30' and 50' lengths)



P

