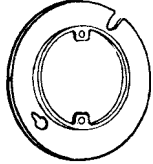
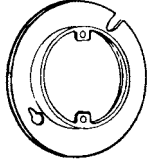
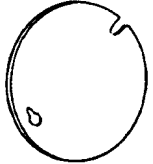
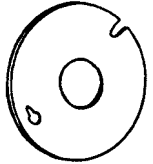
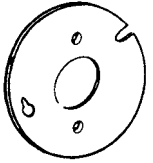
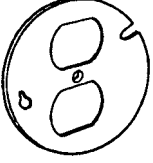


# 4" Octagon and Round Covers

For 4" Octagon and Round Boxes

UL Standard: 514A  
 UL Listed: E2527  
 NEMA: OS-1

	Catalog Number † (Universal No.)	Depth (inches)	Wiring Cubic Inch Capacity	Knockout Description	Wt. Lbs./Kgs. Per 100
 1/2" Raised	8409A (54C31/2)	1/2" Raised	3.5	Ears 2-3/4" C to C	18.0/ 8.16
 5/8" Raised	8409 (54C33/4)	5/8" Raised	4.5	Ears 2-3/4" C to C	20.0/ 9.07
 Flat	8403 (5401)	Flat	0.0	Blank	26.0/ 11.79
 Flat	8413 (54C6)	Flat	0.0	1/2" Knockout	26.0/ 11.79
 Flat	8419LR (54-S)	Flat	0.0	One Single Flush Receptacle 1-13/32" D	21.0/ 9.53
 Flat	8420LR (54-D)	Flat	0.0	Duplex Receptacle	19.0/ 8.62

† 3-1/2" Cover Hole Centerline.