



## EMT Set-Screw Connectors

Concrete tight. Zinc die-cast.



800



803

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	Trade Size	KO Size	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
800Δ	00800	1/2	1/2	50	500	1.143	.375	1.076
801Δ	00801	3/4	3/4	25	250	1.390	.350	1.300
802Δ	00802	1	1	20	200	1.550	.460	1.550
803	00803	1-1/4	1-1/4	10	60	1.930	.636	1.935
804*	00804	1-1/2	1-1/2	10	60	2.200	.707	2.175
805*	00805	2	2	5	30	2.535	.750	2.650
806*†	00806	2-1/2	2-1/2	12	12	2.930	.830	3.300
807*†	00807	3	3	12	12	3.330	.930	3.910
8075*†	08075	3-1/2	3-1/2	6	6	3.500	1.000	4.465
808*†	00808	4	4	6	6	3.665	1.000	4.984


ΔAdd suffix "RH" for Robertson Head Screws.

\*Concrete tight when taped.

†Listed for use with steel and aluminum EMT, IMC, and rigid conduit.



E20643 LR49636

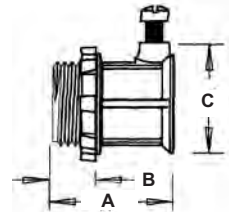

EMT

## EMT Set-Screw Connectors with Insulated Throat

Concrete tight. Zinc die-cast.



800A



803A

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	Trade Size	KO Size	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
800A	80010	1/2	1/2	50	500	1.240	.470	1.076
801A	80110	3/4	3/4	25	250	1.483	.449	1.300
802A	80210	1	1	20	200	1.643	.550	1.550
803A	80310	1-1/4	1-1/4	10	60	2.023	.729	1.935
804A*	80410	1-1/2	1-1/2	10	60	2.293	.800	2.195
805A*	80510	2	2	5	30	2.630	.840	2.650
806A*†	80610	2-1/2	2-1/2	12	12	3.030	.920	3.280
807A*†	80710	3	3	12	12	3.468	1.030	3.910
8075A*†	80711	3-1/2	3-1/2	6	6	3.600	1.088	4.465
808A*†	80810	4	4	6	6	3.758	1.100	4.984

Add suffix "RH" for Robertson Head Screws.

\*Concrete tight when taped.

†Listed for use with steel and aluminum EMT, IMC, and rigid conduit.



E20643 LR49636

