



90° Connectors

Zinc die-cast.

For aluminum and steel
Flex • AC • AC90 • MCI • MCI-A
cable.




CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE
85‡	00893	3/8	1/2	50	500	1.370	.340	1.800	.370-.510
85A*	12510	3/8	1/2	50	500	1.432	.400	1.800	.370-.510

*Provided with insulated throat.

‡Also for MCI-A cable. Refer to page E-25 for cable ranges.

Refer to chart on page E-24 for a list of cable types.

Concrete tight when taped.

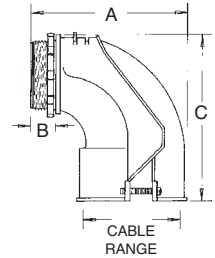

90° SNAP-TITE® Connectors

Zinc die-cast.

With spring steel clip.

For aluminum and steel
Flex • AC • AC90 • MCI • MCI-A
cable.



CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE
85ST‡	00894	3/8	1/2	50	500	1.540	.430	1.800	.370-.510
85AST*	12511	3/8	1/2	50	500	1.600	.490	1.800	.370-.510


*Provided with insulated throat.

‡Also for MCI-A cable. Refer to page E-25 for cable ranges.

Refer to chart on page E-24 for a list of cable types.

SNAP-TITE® products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.

Concrete tight when taped.

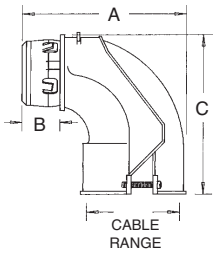


Screw-On Snap-In Connectors

Spring steel clip with non-metallic body. Screws onto 3/8" Flex.



CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B
GFSC38	20737	3/8	1/2	50	500	1.005	.785
GFSC38B	20739	3/8	1/2	-	1000	1.005	.785

For flexible metal conduit only.

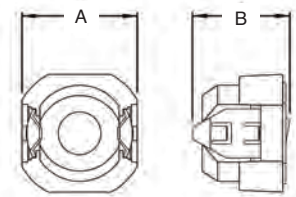

Snaps into KO with 50% less force!