

Duplex SADDLEGRIP® SNAP-TITE® Connectors

Zinc die-cast.
For aluminum and steel
Flex • AC • AC90 • MCI • MCI-A
cable.



CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE
SG3838ST	80152	3/8	1/2	25	100	.455	1.610	.780	(2) .445-.612
SG3838AST*	36210	3/8	1/2	25	100	.605	1.560	.780	(2) .445-.612


*Provided with insulated throat.

With independent securing of the cables, you can use two different size cables.
SNAP-TITE® products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.

Refer to chart on page E-23 for a list of cable types.

Refer to chart on page E-25 for MCI-A cable ranges.

Concrete tight when taped.

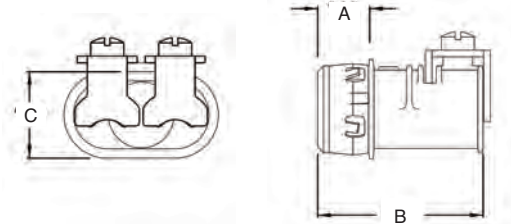

Duplex SADDLEGRIP® Connectors

Zinc die-cast.
For aluminum and steel
Flex • AC • AC90 • MCI • MCI-A
cable.



CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE
SG3838	17383	3/8	1/2	25	100	.452	1.526	.780	(2) .445-.612
SG3838A*	36205	3/8	1/2	25	100	.512	1.586	.780	(2) .445-.612


*Provided with insulated throat.

Refer to chart on page E-23 for a list of cable types.

Refer to chart on page E-25 for MCI-A cable ranges.

Concrete tight when taped.

With independent securing of the cables, you can use two different size cables.

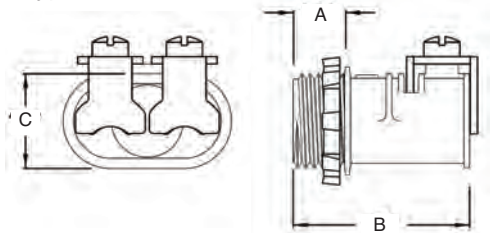


“Take All” Connectors

Single screw saddle type.
For NM • Flex • AC • AC90 • MCI
steel and aluminum jacketed
cables • ACG90 • Teck90.
Zinc die-cast.



L15A

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE	END STOP DIAMETER
L15A*	80040	3/8	1/2	50	500	.984	.420	1.032	.460 - .585	.340 x .430
L16†‡	80060	3/8	1/2	50	500	.923	.375	1.208	.405 - .650	.400 x .580
L160‡	02416	3/8	1/2	50	500	.954	.412	1.092	.370 - .690	.312
L17	34278	1/2	1/2	50	250	1.500	.462	1.416	.630 - .890	.620
L18	34282	3/4	3/4	25	125	1.400	.390	1.750	.820 - 1.040	.818
L19	34287	1	1	25	125	1.640	.443	2.048	1.100 - 1.400	1.030

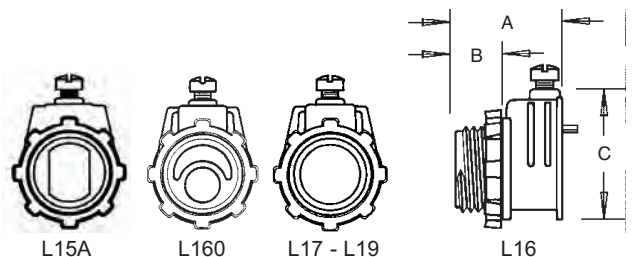

*Provided with insulated throat.

†Listed for flexible cord.

‡Also for MCI-A cable. Refer to page E-25 for cable ranges.

Refer to chart on page E-22 for a list of cable types.

Concrete tight when taped.