

## EMT Set-Screw Couplings

Concrete tight. Zinc die-cast.



810



816


CATALOG NUMBER	UPC/DCI/NAED MFG #018997	Trade Size	UNIT PKG	STD PKG	DIM A	DIM B
810*	00810	1/2	50	500	.950	1.560
811*	00811	3/4	25	250	1.145	1.869
812*	00812	1	15	150	1.435	2.000
813	00813	1-1/4	20	120	1.828	2.500
814	00814	1-1/2	10	60	2.075	2.890
815	00815	2	5	30	2.535	2.567
816†	00816	2-1/2	12	12	3.280	4.000
817†	00817	3	12	12	3.910	4.500
8175†	08175	3-1/2	6	6	4.460	4.814
818†	00818	4	6	6	4.984	5.269

\*Add suffix "RH" for Robertson Head Screws.

†Listed for use with steel and aluminum EMT, IMC, and rigid conduit.



E20643 LR49636

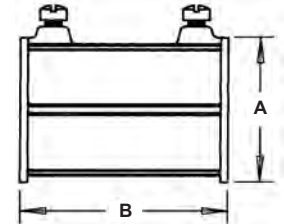

## EMT Compression Couplings

UL listed concrete tight. CSA listed concrete tight/rain tight. Zinc die-cast.



830



836

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	Trade Size	UNIT PKG	STD PKG	DIM A	DIM B
830	00830	1/2	50	500	1.550	1.080
831	00831	3/4	25	250	1.615	1.313
832	00832	1	15	150	1.692	1.616
833	00833	1-1/4	10	100	2.160	2.080
834	00834	1-1/2	10	60	2.290	2.380
835	00835	2	10	60	2.600	2.910
836	00836	2-1/2	12	12	3.070	3.470
837	00837	3	12	12	3.300	4.133
838	00838	3-1/2	6	6	3.330	4.775
839	00839	4	6	6	3.445	5.300



E20643 LR49636

