



Straight Zinc Die-Cast Connectors

For use with metallic and non-metallic liquid-tight conduit, type B only.



LT50



LT250




LT50A

| CATALOG NUMBER | UPC/DCI/NAED MFG #018997 | TRADE SIZE | KO SIZE | UNIT PKG | STD PKG | DIM A | DIM B | DIM C |
|----------------|--------------------------|------------|---------|----------|---------|-------|-------|-------|
| LT38 | 32380 | 3/8 | 1/2 | 25 | 100 | 1.440 | .510 | 1.260 |
| LT50 | 32500 | 1/2 | 1/2 | 25 | 100 | 1.440 | .520 | 1.385 |
| LT75 | 32750 | 3/4 | 3/4 | 10 | 50 | 1.562 | .500 | 1.720 |
| LT100 | 32100 | 1 | 1 | 5 | 25 | 1.825 | .593 | 1.900 |
| LT125 | 32125 | 1-1/4 | 1-1/4 | 5 | 25 | 2.068 | .625 | 2.176 |
| LT150 | 32150 | 1-1/2 | 1-1/2 | 2 | 10 | 2.008 | .625 | 2.507 |
| LT200 | 32200 | 2 | 2 | 2 | 10 | 2.103 | .593 | 3.178 |
| LT250* | 32250 | 2-1/2 | 2-1/2 | 1 | 1 | 3.269 | .980 | 4.218 |
| LT300* | 32300 | 3 | 3 | 1 | 1 | 4.060 | 1.070 | 4.919 |
| LT350* | 32350 | 3-1/2 | 3-1/2 | 1 | 1 | 4.115 | 1.065 | 5.520 |
| LT400* | 32400 | 4 | 4 | 1 | 1 | 4.323 | 1.139 | 5.948 |

*Provided with insulated throat.



E60812 LR49636

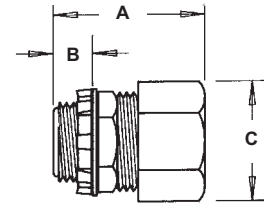

With Insulated Throat

| CATALOG NUMBER | UPC/DCI/NAED MFG #018997 | TRADE SIZE | KO SIZE | UNIT PKG | STD PKG | DIM A | DIM B | DIM C |
|----------------|--------------------------|------------|---------|----------|---------|-------|-------|-------|
| LT38A | 32381 | 3/8 | 1/2 | 25 | 100 | 1.533 | .493 | 1.260 |
| LT50A | 32501 | 1/2 | 1/2 | 25 | 100 | 1.593 | .613 | 1.385 |
| LT75A | 32751 | 3/4 | 3/4 | 10 | 50 | 1.656 | .593 | 1.720 |
| LT100A | 32101 | 1 | 1 | 5 | 25 | 1.935 | .686 | 1.900 |
| LT125A | 32121 | 1-1/4 | 1-1/4 | 5 | 25 | 2.168 | .639 | 2.176 |
| LT150A | 32151 | 1-1/2 | 1-1/2 | 2 | 10 | 2.101 | .680 | 2.507 |
| LT200A | 32201 | 2 | 2 | 2 | 10 | 2.196 | .686 | 3.178 |
| LT250 | 32250 | 2-1/2 | 2-1/2 | 1 | 1 | 3.269 | .980 | 4.218 |
| LT300 | 32300 | 3 | 3 | 1 | 1 | 4.060 | 1.070 | 4.919 |
| LT350 | 32350 | 3-1/2 | 3-1/2 | 1 | 1 | 4.115 | 1.065 | 5.520 |
| LT400 | 32400 | 4 | 4 | 1 | 1 | 4.323 | 1.139 | 5.948 |



E60812 LR49636

