



## EMT Compression Connectors

UL listed concrete tight. CSA listed concrete tight/rain tight. Zinc die-cast.



820




826

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	Trade Size	KO Size	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
820	00820	1/2	1/2	50	500	1.235	.349	1.080
821	00821	3/4	3/4	25	250	1.350	.453	1.313
822	00822	1	1	15	60	1.525	.538	1.616
823	00823	1-1/4	1-1/4	5	25	1.878	.600	2.080
824	00824	1-1/2	1-1/2	10	100	2.020	.607	2.380
825	00825	2	2	10	60	1.995	.645	2.910
826*	00826	2-1/2	2-1/2	12	12	2.775	.860	3.470
827*	00827	3	3	12	12	2.847	.998	4.133
828*	00828	3-1/2	3-1/2	6	6	2.800	.998	4.775
829*	00829	4	4	6	6	3.000	1.007	5.300

\*Listed for use with steel and aluminum EMT, IMC, and rigid conduit.



E20643 LR49636

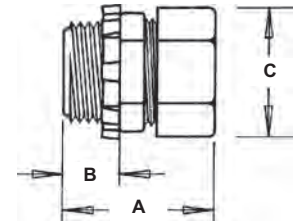

EMT

## EMT Compression Connectors with Insulated Throat

UL listed concrete tight. CSA listed concrete tight/rain tight. Zinc die-cast.



820A



826A

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	Trade Size	KO Size	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
820A	82010	1/2	1/2	50	500	1.346	.442	1.080
821A	82110	3/4	3/4	25	250	1.443	.546	1.313
822A	82210	1	1	15	60	1.620	.631	1.616
823A	82310	1-1/4	1-1/4	5	25	1.971	.693	2.080
824A	82410	1-1/2	1-1/2	10	100	2.120	.700	2.380
825A	82510	2	2	10	60	2.088	.738	2.910
826A*	82610	2-1/2	2-1/2	12	12	2.870	.953	3.470
827A*	82710	3	3	12	12	2.940	1.091	4.133
828A*	82810	3-1/2	3-1/2	6	6	2.900	1.091	4.775
829A*	82910	4	4	6	6	3.150	1.100	5.300

\*Listed for use with steel and aluminum EMT, IMC, and rigid conduit.



E20643 LR49636

