

Strain Relief Cord Connectors



Liquid-tight • Oil-tight.
Furnished with sealing ring.
Zinc die-cast.



CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	CORD RANGE	STD PKG	DIM A	DIM B	DIM C	GROMMET COLOR
CG100750	30750	1	.625-.750	5	2.125	.650	1.370	ORANGE
CG100875	30875	1	.750-.875	5	2.150	.750	1.370	BLACK
CG1001000	31000	1	.875-1.000	5	2.150	.772	1.370	PURPLE



E105706 LR49636

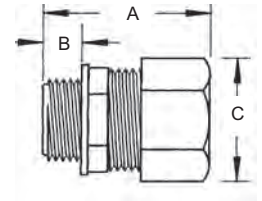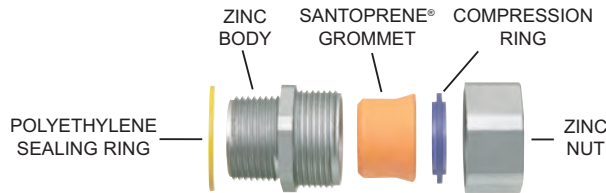

Colorgrip® Strain Relief Cord Connector

Non-metallic • Liquid-tight
Oil-tight. Furnished with
sealing ring and locknut.





CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	CORD RANGE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	GROMMET COLOR
NMCG100750	55000	1	.625-.750	5	30	1.800	.688	1.931	ORANGE
NMCG100875	55002	1	.750-.875	5	30	1.839	.671	1.931	BLACK



E105706 LR49636

When ordering in black - add suffix "BL" to catalog number.

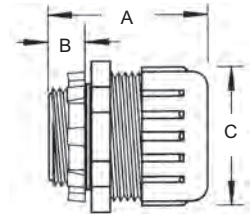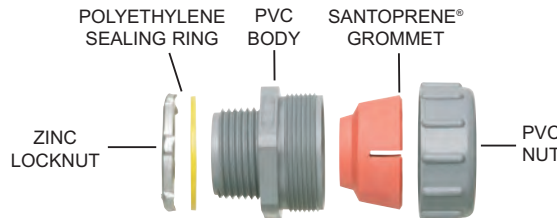

Cable Chart for Arlington Cord Grip Fittings

Check outside wire diameter or manufacturer's specifications for dimensions.

CABLE RANGE	COMMUNICATION & CONTROL WIRE	SJ & SJO	S & SO	SJTO	STO
.100 to .200	22-2 to 14-1 14-1 12-1				
.200 to .300	22-2 20-2 to 20-4 18-2 18-3	18-2 18-3 16-2 16-4	18-2 18-3	18-2 18-3 16-2 16-4	18-2 18-3 16-2 16-2
.300 to .385		16-3		16-3 14-2	
.385 to .472		16-4 14-2 to 14-4 12-2 12-3	16-2 to 16-4 14-2	16-4 14-3 14-4 12-3 12-4	18-4 16-3 14-2

CABLE RANGE	SJ & SJO	S & SO	SJTO	STO
.472 to .625	12-4 10-2 to 10-4	14-3 14-4 12-2 to 12-4 10-3 8-2	10-2 to 10-4	14-3 14-4 12-2 to 12-4 10-2 10-3
.625 to .750	10-4	12-4 10-2 to 10-4 8-2 8-3	10-4	12-4 10-2 to 10-4
.750 to .875		8-4 8-5 6-2 6-3		
.875 to 1.000		6-4 4-2 4-3		6-4 4-3