



Arlington


Part No.	UPC No.	Page	Part No.	UPC No.	Page	Part No.	UPC No.	Page	Part No.	UPC No.	Page
PVC106	12512	F-1	RW29	95290	I-8	SG50ST	80150	E-13	TVB713	09713	N-3, P-12
PVC129	73129	F-1	RW3	95300	I-8	SG75	18075	E-13	TVB810	24184	N-6
PVC660	73660	F-2	RW30	95301	I-8	SG75A	17751	E-13	TVB810GC	24185	N-6
PVC662	73662	F-2	RW31	95310	I-8	SG75AST	17755	E-13	TVBR505K	09682	N-1, P-11
PVC85	00085	F-4	RW32	95320	I-8	SG75ST	18080	E-13	TVBR505KGC	08973	N-1, P-11
R			RW33	95330	I-8	SL100	13100	I-7	TVBRA1K	24180	N-5, P-13
RGD100	51933	I-1, O-11	RW34	95340	I-8	SL125	13125	I-7	TVBRA1KGC	24182	N-5, P-13
RGD100C	51939	I-2	RW35	95350	I-8	SL150	13150	I-7	TVBRA2K	24181	N-5, P-13
RGD125	51934	I-1, O-11	RW36	95360	I-8	SL200	13200	I-7	TVBRA2KGC	24183	N-5, P-13
RGD125C	51940	I-2	RW37	95370	I-8	SL250	13250	I-7	TVBRA3K	24195	N-5, P-13
RGD150	51935	I-1, O-11	RW38	95380	I-8	SL300	13300	I-7	TVBRA3KGC	24196	N-5, P-13
RGD150C	51941	I-2	RW39	95390	I-8	SL350	13350	I-7	TVBSS505	37955	N-2, P-10
RGD200	51936	I-1, O-11	RW4	95400	I-8	SL400	13400	I-7	TVBSS507	37956	N-2, P-10
RGD200C	51942	I-2	RW40	95401	I-8	SL50	13500	I-7	TVBS613	09633	N-2, P-10
RGD50	51930	I-1, O-11	RW41	95410	I-8	SL500	13501	I-7	TVBS613BL	09660	N-2, P-10
RGD50C	51937	I-2	RW42	95420	I-8	SL600	13600	I-7	TVBU505	09680	N-1, P-11
RGD75	51932	I-1, O-11	RW43	95430	I-8	SL75	13750	I-7	TVBU505BL	09681	N-1, P-11
RGD75C	51938	I-2	RW44	95440	I-8	SMC4	42305	E-5	TVBU505BLGC	08975	N-1, P-11
RTS12	10490	R-1	RW45	95450	I-8	SMC4F	42315	E-5	TVBU505GC	08974	N-1, P-11
RTS1221	10491	R-1	RW5	95500	I-8	SMC8	42307	E-5	TVBU507	09661	N-1, P-11
RTS4	10492	R-1	RW6	95600	I-8	SP100	17100	R-12	TVBU507BL	09662	N-1, P-11
RTS402	00916	R-1	RW7	95700	I-8	SP360	17360	F-4	TVBU507BLGC	08977	N-1, P-11
RTS421	10493	R-1	RW8	95800	I-8	SP362	17361	F-4	TVBU507GC	08976	N-1, P-11
RTSB1209	00912	R-1	RW9	95900	I-8	SP363	17362	F-4			
RTSB405	00910	R-1	S			SP364	17363	F-4	U		
RTSB409	00911	R-1	SB1	18001	C-9, R-9	SP365	17364	F-4	UF50	36500	C-5
RTSE1209	00912	R-1	SB10	18010	C-9, R-9	T			UF75	51302	C-5
RTSE405	00914	R-1	SB13	40115	C-9, O-12, R-9	T205	38060	C-1	W		
RTSE409	00915	R-1	SB130	40130	C-9, O-12, R-9	T23A	38065	C-1	WB112	52952	O-2
RW1	95100	I-8				T23C	38061	C-1	WB200	52953	O-2
RW10	95101	I-8				T23E	38062	C-1	WB500	52950	O-2
RW11	95110	I-8	SB3	18050	C-9, R-9	T23F	38066	C-1	WB875	52950	O-2
RW12	95120	I-8	SB30	18053	C-9, R-9	T23H	38063	C-1	WC1001	53101	C-5
RW13	95130	I-8	SBS	18055	R-12	T23T	38067	C-1	WTC100	58732	C-12
RW14	95140	I-8	SC100	06300	R-2	T23W	38068	C-1	WTC125	58733	C-12
RW15	95150	I-8	SC5	18058	M-4	TL20	38084	O-9	WTC150	58734	C-12
RW16	95160	I-8	SG38	18065	E-13	TL20P	38087	O-9	WTC200	58735	C-12
RW17	95170	I-8	SG380	18060	E-13	TL25	38085	O-9	WTC210	58736	C-12
RW18	95180	I-8	SG380A	80140	E-13	TL25P	38088	O-9	WH1	58100	I-6
RW19	95190	I-8	SG380AST	80148	E-13	TL50	38086	O-9	WH10	58101	I-6
RW2	95200	I-8	SG3838	17383	E-12	TL50P	38089	O-9	WH11	58103	I-6
RW20	95201	I-8	SG3838A	36205	E-12	TVB613	09630	N-4	WH12	58105	I-6
RW21	95210	I-8	SG3838AST	36210	E-12	TVB613BL	09634	N-4	WH2	58200	I-6
RW22	95220	I-8	SG3838ST	80152	E-12	TVB613BLGC	08969	O-7	WH3	58300	I-6
RW23	95230	I-8	SG38A	80138	E-13	TVB613C	09631	N-2, N-3, N-4, P-10, P-12	WH4	58400	I-6
RW24	95240	I-8	SG38AST	80144	E-13	TVB613GC	08968	O-7	WH5	58500	I-6
RW25	95250	I-8	SG40	01740	E-13	TVB712	09712	N-3, P-12	WH6	58600	I-6
RW26	95260	I-8	SG50	07500	E-13	TVB712BK	12781	N-5, P-13	WH7	58700	I-6
RW27	95270	I-8	SG50A	37501	E-13	TVB712BKGC	12782	N-5, P-13	WH8	58800	I-6
RW28	95280	I-8	SG50AST	17501	E-13				WH9	58900	I-6

STANDARDS

PRODUCT GROUP	UL STANDARD NUMBER	UL FILE NUMBER	UL CONTROL NUMBER	CSA FILE NUMBER	FED SPEC NUMBER	NEMA STANDARD
Liquid-Tight Fittings	UL 514B	E60812	351F	LR49636	A-A-50552	FB-1
EMT Fittings	UL 514B	E20643	365D	LR49636	A-A-50553	FB-1
Non-Metallic Cable Connectors	UL 514B	E28474	388D	LR49636	A-A-50552	FB-1
Flexible Cord Connectors	UL 514B	E105706	1B64	LR49636	A-A-50552	FB-1
Armored Cable Connectors	UL 514B	E18304	372D	LR49636	A-A-50552	FB-1
Service Entrance Cable Fittings	UL 514B	E66990	282F	LR49636	A-A-50563	FB-1
Grounding and Bonding Equipment	UL 467	E75814	910F	LR49636	A-A-50552	FB-1
Conduit Bodies	UL 514A UL 514B	E28474	5B36	LR49636	A-A-50563	FB-1
Conduit Fittings-Rigid	UL 514B	E60812	351F	LR49636	A-A-50553	FB-1
MC Cable Connectors	UL 514B	E123751	388E	LR49636	A-A-50552	FB-1
Grounding Lugs	UL 514B	E86540	910F	LR49636	A-A-50552	FB-1
Flush Device Box Covers	UL 514A	E48106	910F	LR49636	A-A-50563	FB-1
Non-Metallic Outlet Boxes	UL 514C	E170558	6D39	LR49636	A-A-50563	FB-1

Reducing Washers

Plated steel.

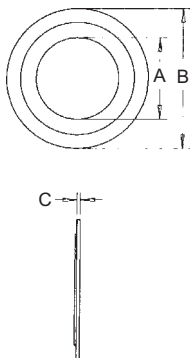

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
RW1	95100	3/4 x 1/2	250	1000	.870	1.420	.035
RW2	95200	1 x 1/2	100	400	.870	1.710	.035
RW3	95300	1 x 3/4	100	400	1.060	1.710	.035
RW4	95400	1-1/4 x 1/2	200	200	.870	2.080	.035
RW5	95500	1-1/4 x 3/4	200	200	1.060	2.080	.035
RW6	95600	1-1/4 x 1	200	200	1.380	2.080	.035
RW7	95700	1-1/2 x 1/2	100	100	.870	2.635	.035
RW8	95800	1-1/2 x 3/4	100	100	1.060	2.635	.035
RW9	95900	1-1/2 x 1	100	100	1.335	2.635	.035
RW10	95101	1-1/2 x 1-1/4	100	100	1.690	2.635	.035
RW11	95110	2 x 1/2	50	50	.870	3.265	.035
RW12	95120	2 x 3/4	50	50	1.060	3.265	.035
RW13	95130	2 x 1	50	50	1.335	3.265	.035
RW14	95140	2 x 1-1/4	50	50	1.690	3.265	.035
RW15	95150	2 x 1-1/2	50	50	1.935	3.265	.035
RW16	95160	2-1/2 x 1/2	50	50	.870	3.265	.035
RW17	95170	2-1/2 x 3/4	50	50	1.060	3.265	.035
RW18	95180	2-1/2 x 1	50	50	1.370	3.265	.035
RW19	95190	2-1/2 x 1-1/4	50	50	1.750	3.265	.035
RW20	95201	2-1/2 x 1-1/2	50	50	1.935	3.265	.035
RW21	95210	2-1/2 x 2	50	50	2.425	3.265	.035
RW22	95220	3 x 1/2	25	25	.870	4.490	.040
RW23	95230	3 x 3/4	25	25	1.060	4.490	.040
RW24	95240	3 x 1	25	25	1.360	4.490	.045
RW25	95250	3 x 1-1/4	25	25	1.750	4.490	.040
RW26	95260	3 x 1-1/2	25	25	1.935	4.490	.040
RW27	95270	3 x 2	25	25	2.424	4.490	.040
RW28	95280	3 x 2-1/2	25	25	2.940	4.490	.040
RW29	95290	3-1/2 x 1/2	10	10	.870	5.000	.060
RW30	95301	3-1/2 x 3/4	10	10	1.060	5.000	.060
RW31	95310	3-1/2 x 1	10	10	1.360	5.000	.060
RW32	95320	3-1/2 x 1-1/4	10	10	1.750	5.000	.060
RW33	95330	3-1/2 x 1-1/2	10	10	1.935	5.000	.060
RW34	95340	3-1/2 x 2	10	10	2.425	5.000	.060
RW35	95350	3-1/2 x 2-1/2	10	10	2.920	5.000	.060
RW36	95360	3-1/2 x 3	10	10	3.560	5.000	.060
RW37	95370	4 x 1/2	10	10	.870	5.500	.065
RW38	95380	4 x 3/4	10	10	1.060	5.500	.065
RW39	95390	4 x 1	10	10	1.360	5.500	.065
RW40	95401	4 x 1-1/4	10	10	1.715	5.500	.065
RW41	95410	4 x 1-1/2	10	10	1.970	5.500	.065
RW42	95420	4 x 2	10	10	2.435	5.500	.065
RW43	95430	4 x 2-1/2	10	10	2.920	5.500	.065
RW44	95440	4 x 3	10	10	3.560	5.500	.065
RW45	95450	4 x 3-1/2	10	10	4.050	5.500	.065



E181788 LR104691