


## SNAP<sup>2</sup>IT<sup>®</sup> Connectors

Zinc die-cast.

For AC • MCI-A • HCF steel and aluminum cable • Flexible metal conduit steel and aluminum (regular and reduced wall) • MCI cable continuous corrugated aluminum • AC90.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
38AST*	00070	3/8	1/2	50	500	1.410	.850	.405	1.000	.405 - .612
38A*	00038	3/8	1/2	50	500	1.410	.850	.405	1.000	.405 - .612
380ST	00381	3/8	1/2	50	500	1.280	.850	.400	1.000	.405 - .612
380AST*	00382	3/8	1/2	50	500	1.280	.850	.400	1.000	.405 - .612

\*Provided with insulated throat.

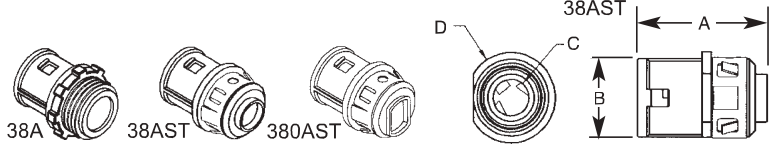

38AST



40AST

### With Insulated Throat and Red Tinted Inside Clip

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
40AST	00041	3/8	1/2	50	500	1.410	.850	.405	1.000	.485 - .612
400AST	40347	3/8	1/2	50	500	1.280	.850	.400	1.000	.485 - .612

Refer to chart on page E-22 for a list of cable types.

Concrete tight when taped.

Flexible metal conduit, CSA listed with anti-short bushing (UL not applicable).

SNAP-TITE<sup>®</sup> and SNAP<sup>2</sup>IT<sup>®</sup> products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.

See page E-25 for MCI-A cable ranges.



Flex • AC • MC

FOR  
EASIER MCI/AC  
INSTALLATIONS...  
See

3810AST to 7510AST  
on Page E-2

### NO TOOLS!

- Safe and fast installations
- Saves about 17 seconds per fitting!
- Competitively priced

SNAP<sup>2</sup>IT Connectors are EASY to Install...



Snap onto cable and give a clockwise twist.




Just snap into box!

And EASY to Remove...




Using a screwdriver, lift the ring and twist off.

COMPARE...

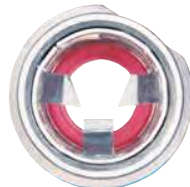

38AST

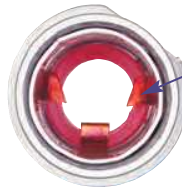

40AST

**RED TINTING** means 'OPEN TANG' Design!

It gives you more room inside the fitting for easy insertion of wires.

The redesigned front end makes it easier than ever to snap the fitting into box!