




Siding Box Kits

For smooth vertical mounting of fixtures and receptacles on sided structures. Paintable. UV rated plastic for long outdoor life.

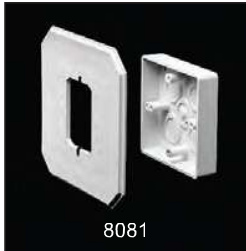

8081



8081F



8082F (for 1/2" or less)



8081FC




8081FB

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	SIDING TYPE	USES	UNIT PKG	STD PKG	STYLE
8081*	80812	All Types	Fixtures Devices	25	25	w/o Flange
8081F*	80814	All Types	Fixtures Devices	25	25	w/ Flange
8082F*	32240	1/2" or Less	Fixtures Devices	25	25	w/ Flange
8081FC*	10939	All Types	Fixtures Devices	25	25	Cover Only
8081FB*	10941	All Types	Fixtures Devices	25	25	Box Only

*Add suffix "GC" to Catalog # when ordering in Canada, for example 8081FGC.



E170558 LR49636

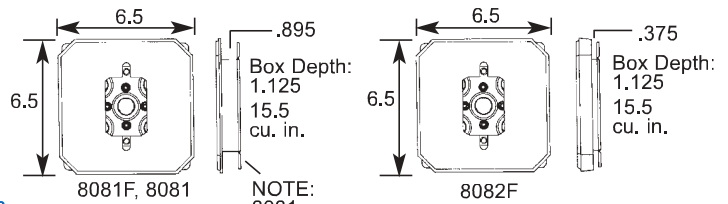

Features and Benefits

- UL Listed electrical box
- Works on all siding types – Before or After the siding is up!
- Flanges may be removed for retrofit work
- Textured, paintable surface
- NM cable connector included

For Installation Instructions 'AFTER Siding is Up' see Below. For Installation Instructions 'BEFORE Siding is Up' see Page L-2.

Installation Instructions

AFTER Siding is Up... Without Flange (8081 & 8081DBL)

NOTE: 8081F, 8081FDBL, 8082F, 8091F, and 8091FDBL may also be installed when siding is already up – Score and break off flanges before step one (below).



1 Disconnect electrical power. Place box section in desired location and pencil outline onto siding.



2 Cut along pencil line with razor knife and remove vinyl siding.



3 Mount box section to substrate. Caulk as required.



4 Place siding block over box section (8081 shown).



5 Connect wires and install fixture per manufacturer's instructions.

Siding Mounting Blocks