

45° Connectors

Zinc die-cast.
For aluminum and steel
Flex • AC • MCI cable.




CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE	END STOP DIAMETER
4501	04501	3/8	1/2	50	500	.382	1.132	1.588	.445-.612	.620
4502	04502	1/2	1/2	25	250	.382	1.150	1.775	.620-.895	.635

Refer to chart on page E-23 for a list of cable types.
Concrete tight when taped.



E60812 LR49636

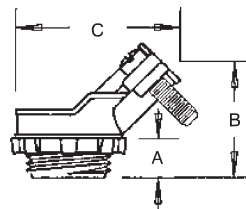

45° SNAP-TITE® Connectors

Zinc die-cast.
With spring steel clip.
For aluminum and steel
Flex • AC • MCI cable.



CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE	END STOP DIAMETER
4501ST	06002	3/8	1/2	50	500	.382	1.132	1.588	.445-.612	.620
4502ST	06004	1/2	1/2	25	250	.382	1.150	1.775	.620-.895	.635


Refer to chart on page E-23 for a list of cable types.

SNAP-TITE® products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.

Concrete tight when taped.



E60812 LR49636

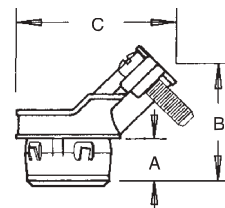

90° SNAP-TITE® Connectors

Zinc die-cast.
With spring steel clip.
For aluminum and steel
Flex • AC • AC90 • MCI cable.



CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	CABLE RANGE
850ST	80154	3/8	1/2	50	500	1.540	.430	1.800	.440-.750
850AST*	80156	3/8	1/2	50	500	1.600	.490	1.775	.440-.750
851ST‡	80158	1/2	1/2	25	250	1.600	.430	2.140	.642-1.075
851AST*‡	80160	1/2	1/2	25	250	1.651	.490	2.145	.648-1.081

*Provided with insulated throat.

‡Also for MCI-A cable. Refer to page E-25 for cable ranges.

Refer to chart on page E-24 for a list of cable types.

SNAP-TITE® products have been tested and listed by UL in accordance with UL's ground fault requirements. For additional information see page 6.

Concrete tight when taped.



372D LR49636

