



Arlington

Fan & Fixture Mounting Boxes

Ceiling fan/fixture pan boxes.



Features and Benefits

- No loose parts to misplace – totally self-contained!
- Fan/fixture installation screws are “parked”...ready for easy fan/fixture bracket installation!
- Works well on double joists or wood I-beams
- Combination hex/Phillips head screws for easy installation with power screwdrivers
- Two hour fire rating
- UL rated: 70 lb. fan, 200 lb. fixture; CSA rated: 50 lb. fan/fixture


CATALOG NUMBER	UPC/DCI/NAED MFG #018997	DESCRIPTION / STYLE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
FB405	72185	For 1/2" or 5/8" Drywall 6.0 Cu. In.	25	25	2.315	.570	4.250
FB4050*	28101	For 1/2" or 5/8" Drywall 6.0 Cu. In.	100	100	2.315	.570	4.250
FB407	72177	For 5/8" Drywall 8.0 Cu. In.	25	25	2.315	.660	4.250
FB4070	28102	For 5/8" Drywall 8.0 Cu. In.	100	100	2.315	.660	4.250

*Bulk packing for lower cost.

Refer to chart on page Q-17 for load ratings and number of single conductors.



E170558 LR49636

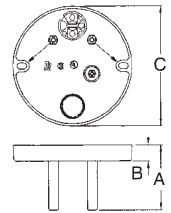

Each fan/fixture box includes...

A ready-to-tighten center screw, installed NM cable connector, mud cover, second KO, and two screws for fan/fixture bracket installation (screwed in place until removed by installer).

Note: Install fan or fixture (not included) in accordance with manufacturer's instructions and all local applicable electrical codes, using the parked screws provided.

Fan & Fixture Mounting Boxes

Boxes accommodate 1/2" or 5/8" drywall with 3/4" furring strips or hat channel.



FB412




FB423

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	DESCRIPTION / STYLE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
FB412	72189	Pan Box 14.4 Cu. In.	25	25	3.000	1.250	4.250
FB423	72190	Press-On Box 19.5 Cu. In.	25	25	3.000	1.250	4.250

Refer to chart on page Q-17 for load ratings and number of single conductors.




E170558 LR49636

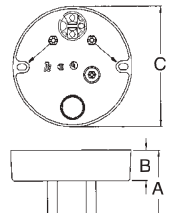

Each fan/fixture box includes...

A ready-to-tighten center screw, installed NM cable connector, mud cover, second KO, and two screws for fan/fixture bracket installation (screwed in place until removed by installer).

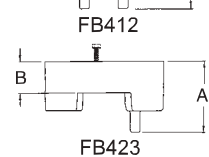

Note: Install fan or fixture (not included) in accordance with manufacturer's instructions and all local applicable electrical codes, using the parked screws provided.

FB412



Features and Benefits

- No loose parts to misplace – totally self-contained!
- For use with 1/2" or 5/8" drywall with 3/4" furring strips or hat channel
- Also for double 5/8" drywall
- Attaches securely to joist through shipped-in-place center screw
- Two hour fire rating
- UL rated: 70 lb. fan; 200 lb. fixture; CSA rated: 50 lb. fan/fixture

Fan/Fixture Boxes