



Arlington

Fan & Fixture Mounting Box



Our deepest L-shaped fan/fixture box mounts securely to single or double joists with a shipped-in-place center screw.

Locator posts for positioning of bracket installation screws



| CATALOG NUMBER | UPC/DCI/NAED MFG #018997 | DESCRIPTION / STYLE | UNIT PKG | STD PKG | DIM A | DIM B | DIM C |
|----------------|--------------------------|--|----------|---------|-------|-------|-------|
| FB444 | 72187 | For 1/2" or 5/8" Drywall 25.6 Cu. In. | 25 | 25 | 5.330 | 4.000 | 4.716 |

Refer to chart on page Q-17 for load ratings and number of single conductors.

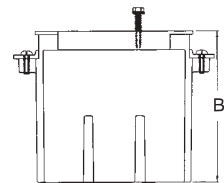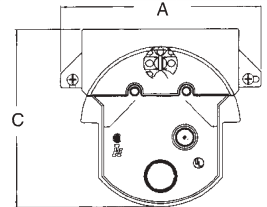

FB444 includes...

A ready-to-tighten center screw, installed NM cable connector, mud cover, multiple KOs, and two screws for fan/fixture bracket installation (screwed in place until removed by installer).

Installation Instructions

Features and Benefits

- No loose parts to misplace – totally self-contained!
- Arlington's deepest fan box!
- Easy wire access
- Locator posts assure proper positioning of fan/fixture bracket
- Fan/fixture installation screws are "parked"...ready for easy fan/fixture bracket installation!
- UL rated: 70 lb. fan, 200 lb. fixture; CSA rated: 50 lb. fan/fixture



1. Position box alongside joist. Tighten center screw, mounting box to joist.




2. Position mounting bracket over locator posts to assure proper position.



3. Remove captive bracket installation screws. Use them to mount fan/fixture bracket.



Optional
If necessary, the bottom of the box can be opened to access wires.

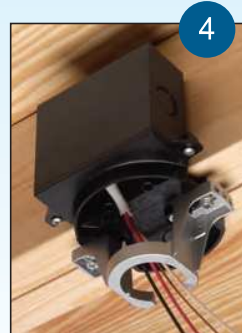

4. Pull wires through knockout. (Installation of drywall not shown.)

Note: Install fan or fixture (not included) in accordance with manufacturer's instructions and all local applicable electrical codes, using the parked screws provided.