

ONE-BOX™ Vapor *New!* Boxes for Fixtures

Versatile, non-conductive
Fixture box for new
construction. Mounts directly
to a wood or steel stud.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	DESCRIPTION/ CU. IN.	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
F426F	06903	Round Screw-on 28.0	20	20	6.250	4.230	.500
FN430F	15100	Round Nail-on 30.5	20	20	6.250	4.230	.500
FN440F*	15120	Round Nail-on 39.5	20	20	6.250	4.230	1.250


* For use with double drywall installation.
Add suffix "GC" to Catalog # when ordering in Canada, for example F426FGC.
Refer to chart on page Q-17 for load ratings and number of single conductors.
Refer to P-8 for additional Vapor Boxes.



F426F



FN430F

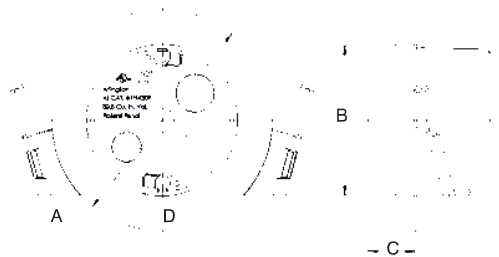

Features and Benefits


- Non-metallic, non-conductive
- Ships with captive mounting screws
- Includes additional gasket material for knockouts
- Two hour fire rating for Double Drywall version ONLY

Steel ONE-BOX™

Designed for new construction
or retrofit, side-mounts to a
joist for a super secure,
fan-rated installation - with
no wobble.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	DESCRIPTION/ STYLE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
FBS1423	76190	2-3/8" Box Depth / 23.0 Cu. In.	10	10	3.572	4.250	2.375

Mounts on Side of Joist.
Refer to chart on page Q-17 for load
ratings and number of single conductors.

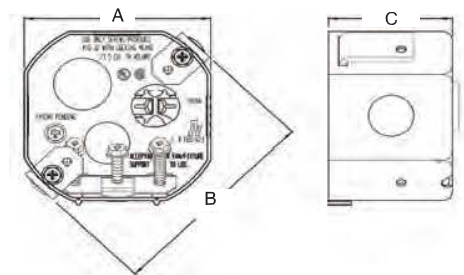

Features and Benefits

- Fast, easy installation.
- Tabs for 1/2" positioning
- Installation screws ship captive
- Installed NM cable connector
- Two # 10 thread holes, including screws for fan
- Two # 8 thread holes, including screws for fixtures.
- UL rated 70 lb. fan/fixture;
cUL rated 50 lb.fan/fixture

NEW CONSTRUCTION



RETROFIT

