



**Straight Zinc Die-Cast Connectors**

For use with metallic and non-metallic liquid-tight conduit, type B only.



LT50



LT250




LT50A

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
LT38	32380	3/8	1/2	25	100	1.440	.510	1.260
LT50	32500	1/2	1/2	25	100	1.440	.520	1.385
LT75	32750	3/4	3/4	10	50	1.562	.500	1.720
LT100	32100	1	1	5	25	1.825	.593	1.900
LT125	32125	1-1/4	1-1/4	5	25	2.068	.625	2.176
LT150	32150	1-1/2	1-1/2	2	10	2.008	.625	2.507
LT200	32200	2	2	2	10	2.103	.593	3.178
LT250*	32250	2-1/2	2-1/2	1	1	3.269	.980	4.218
LT300*	32300	3	3	1	1	4.060	1.070	4.919
LT350*	32350	3-1/2	3-1/2	1	1	4.115	1.065	5.520
LT400*	32400	4	4	1	1	4.323	1.139	5.948

\*Provided with insulated throat.



E60812 LR49636

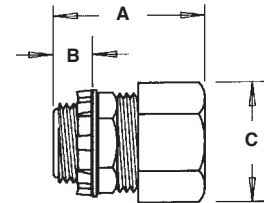

**With Insulated Throat**

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
LT38A	32381	3/8	1/2	25	100	1.533	.493	1.260
LT50A	32501	1/2	1/2	25	100	1.593	.613	1.385
LT75A	32751	3/4	3/4	10	50	1.656	.593	1.720
LT100A	32101	1	1	5	25	1.935	.686	1.900
LT125A	32121	1-1/4	1-1/4	5	25	2.168	.639	2.290
LT150A	32151	1-1/2	1-1/2	2	10	2.101	.680	2.633
LT200A	32201	2	2	2	10	2.196	.686	3.156
LT250	32250	2-1/2	2-1/2	1	1	3.269	.980	4.218
LT300	32300	3	3	1	1	4.060	1.070	4.919
LT350	32350	3-1/2	3-1/2	1	1	4.115	1.065	5.520
LT400	32400	4	4	1	1	4.323	1.139	5.948



E60812 LR49636

