



## 90° Zinc Die-Cast Connectors

For use with metallic and non-metallic liquid-tight conduit, type B only.



LT9050



LT90150



LT9050A




LT90150A

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
LT9038	32938	3/8	1/2	10	50	2.062	.520	2.340
LT9050	32950	1/2	1/2	10	50	2.128	.525	2.312
LT9075	32970	3/4	3/4	10	50	2.515	.510	2.664
LT90100	32910	1	1	5	25	2.758	.675	3.640
LT90125	32913	1-1/4	1-1/4	2	10	3.362	.700	3.912
LT90150	32915	1-1/2	1-1/2	2	10	3.500	.604	4.368
LT90200	32920	2	2	2	10	4.106	.680	4.865
LT90250*	32925	2-1/2	2-1/2	1	1	5.500	.870	6.225
LT90300*	32930	3	3	1	1	6.000	.950	6.720
LT90350*	32935	3-1/2	3-1/2	1	1	6.625	.950	7.450
LT90400*	32940	4	4	1	1	7.000	.950	8.000

\*Provided with insulated throat.



E60812 LR49636

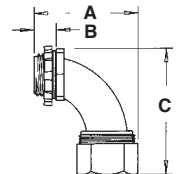

## With Insulated Throat

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C
LT9038A	32931	3/8	1/2	10	50	2.137	.595	2.340
LT9050A	32951	1/2	1/2	10	50	2.203	.595	2.312
LT9075A	32971	3/4	3/4	10	50	2.590	.585	2.664
LT90100A	32911	1	1	5	25	2.906	.750	3.640
LT90125A	32912	1-1/4	1-1/4	2	10	3.473	.775	3.912
LT90150A	32955	1-1/2	1-1/2	2	10	3.575	.679	4.368
LT90200A	32921	2	2	2	10	4.206	.755	4.865
LT90250	32925	2-1/2	2-1/2	1	1	5.000	.945	6.225
LT90300	32930	3	3	1	1	6.000	1.025	6.720
LT90350	32935	3-1/2	3-1/2	1	1	6.625	1.025	7.450
LT90400	32940	4	4	1	1	7.000	1.025	8.000



E60812 LR49636

