

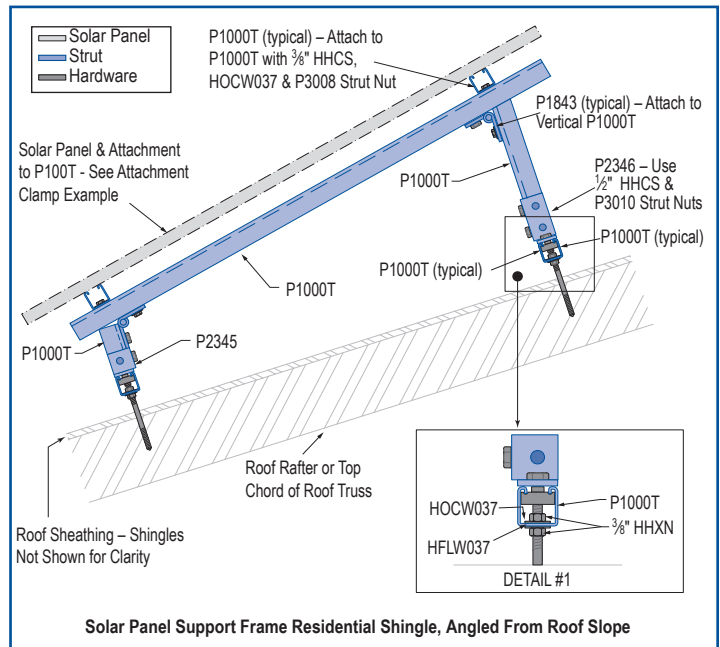
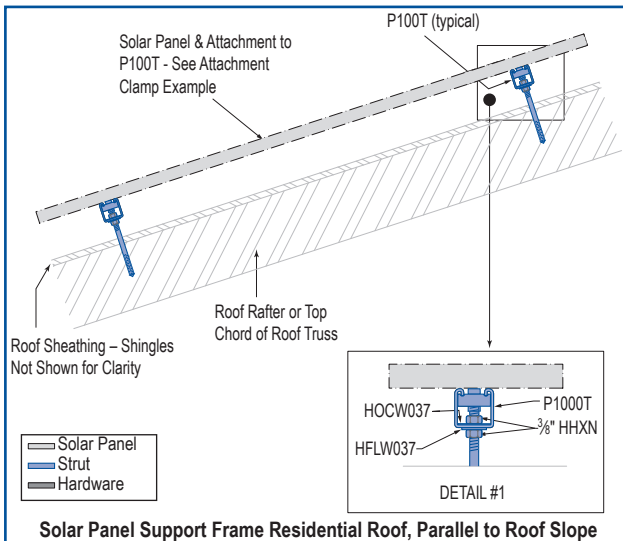
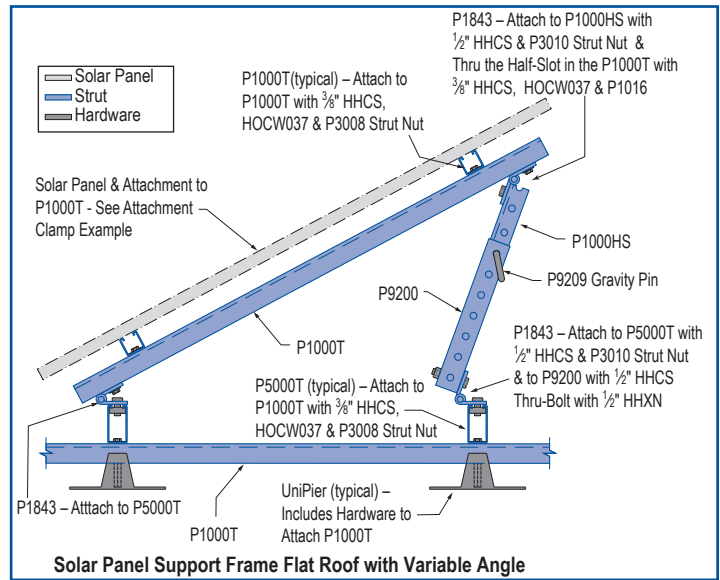


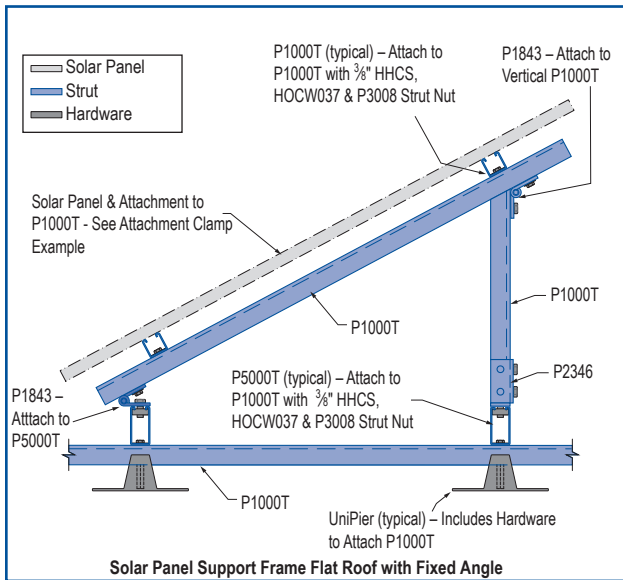

TYPICAL SOLAR INSTALLATION

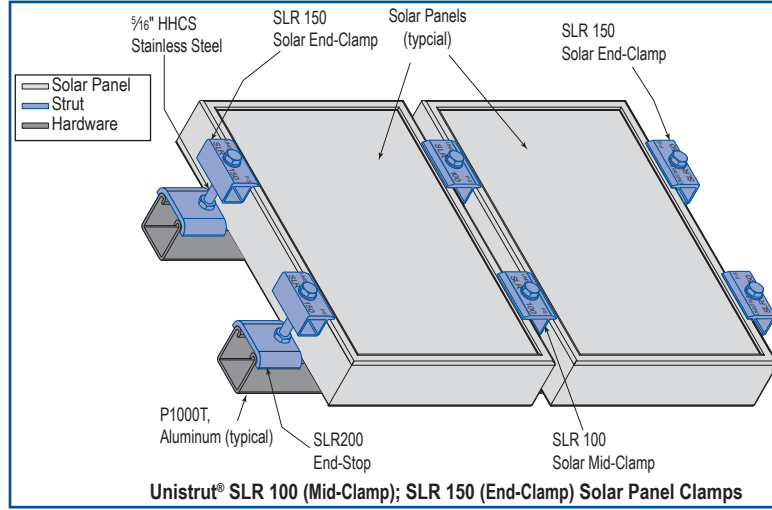

1 5/8" Channel

Telestrut

Nuts & Hardware

General Fittings

Pipe/Conduit Supports

Electrical Fittings


Concrete Inserts

Solar

UniPier®


P1000 Series

P1000 SS

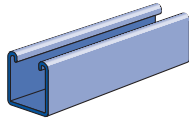

Wt/100 Ft: 190 Lbs (283 kg/100m)


P1001 SS

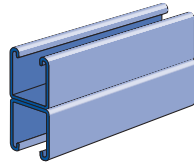

Wt/100 Ft: 380 Lbs (566 kg/100m)

P1000HS SS

 
9/16" (14.3) Dia. Holes
1 7/8" (47.6) on Center



Wt/100 Ft: 185 Lbs (275 kg/100m)

P1000T SS


Slots are
1 1/8" (28.6) x 9/16" (14.3)
2" (50.8) on Center

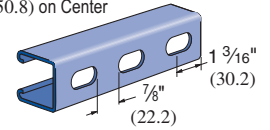

Wt/100 Ft: 185 Lbs (275 kg/100m)


P1100 Series

P1100 SS

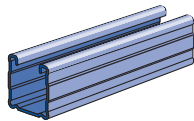

Wt/100 Ft: 142 Lbs (211 kg/100m)


P1101 SS

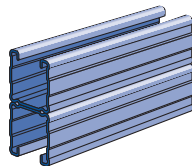

Wt/100 Ft: 284 Lbs (422 kg/100m)

P1100HS SS

 
9/16" (14.3) Dia. Holes
1 7/8" (47.6) on Center



Wt/100 Ft: 136 Lbs (202 kg/100 m)

P1100T SS

Slots are
1 1/8" (28.6) x 9/16" (14.3)
2" (50.8) on Center

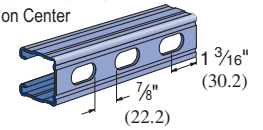


Wt/100 Ft: 136 Lbs (202 kg/100m)

P3000 Series


P3000 SS

Wt/100 Ft: 170 Lbs (253 kg/100m)

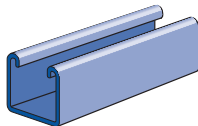

P3000HS SS

 
9/16" (14.3) Dia. Holes
1 7/8" (47.6) on Center



Wt/100 Ft: 165 Lbs (112 kg/100m)

P3000T SS


Slots are
1 1/8" (28.6) x 9/16" (14.3)
2" (50.8) on Center

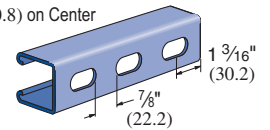

Wt/100 Ft: 165 Lbs (112 kg/100m)


P3300 Series

 P3300 SS



Wt/100 Ft: 135 Lbs (201 kg/100m)


P3301 SS

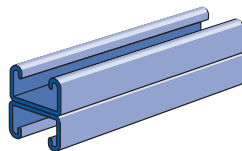

Wt/100 Ft: 270 Lbs (402 kg/100m)

P3300HS SS

 
9/16" (14.3) Dia. Holes
1 7/8" (47.6) on Center



Wt/100 Ft: 130 Lbs (193 kg/100m)

P3300T SS


Slots are
1 1/8" (28.6) x 9/16" (14.3)
2" (50.8) on Center

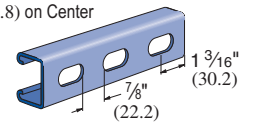

Wt/100 Ft: 130 Lbs (193 kg/100m)

P4000 Series

 
P4000 SS



Wt/100 Ft: 82 Lbs (122 kg/100m)

P4000HS SS

 
9/16" (14.3) Dia. Holes
1 7/8" (47.6) on Center



Wt/100 Ft: 79 Lbs (110 kg/100m)


P4000T SS

Slots are
1 1/8" (28.6) x 9/16" (14.3)
2" (50.8) on Center

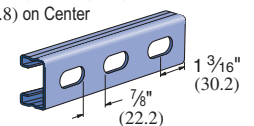


Wt/100 Ft: 79 Lbs (110 kg/100m)

 P6000 SS



Wt/100 Ft: 37 Lbs (55 kg/100m)

 P7000 SS



Wt/100 Ft: 36 Lbs (54 kg/100m)



1 1/4" System

F375PU-CNHD	196
F375PU-FN-000	197
F500E-999	197
F500PU	196
F500PU	196
F500PU	203
F500PU-000	197
F500PU-FN-000	197
F50PU	200

1 3/16" System

F50PU-500SP	197
F625E-999	197
F625PU	196
F625PU-000 thru F625PU-350	197
F625PU-125	197
F625PU-FN-000	197

Fiberglass System

F750E-999	197
F750PU	196
F750PU-FN-000	197
FAIC-EC	198
FCVHPU	202
FPCR	201
FPS	201
FRGBC	203
FUB	198

Special Metals

G 11282	236
G 12282	236
G 61281	236
G 62281	236
G 91282	236
G 92282	236
G11281	222
G12281	222

PrimeAngle

G124	225
G31183 thru G31383	223
G600 thru G639	224
G603 thru G642	223
G61141 thru G61143	222
G61181 thru G61183	222

Metal Grating

G61221 thru G61223	222
G61241 thru G61243	222
G61281 thru G61283	222
G61341 thru G61343	222
G61381 thru G61383	222
G62141 thru G62143	222
G62181 thru G62183	222

Roofwalk

G62221 thru G62223	222
G62241 thru G62243	222
G62281 thru G62283	222
G62341 thru G62343	222
G640	225
G714	225
G900 thru G904	226
G91141 thru G91143	222

Index

G91181 thru G91183	222
G91221 thru G91223	222
G91241 thru G91243	222
G91281 thru G91283	222
G91341 thru G91343	222
G91381 thru G91383	222
G92141 thru G92143	222
G92181 thru G92183	222
G92221 thru G92223	222
G92241 thru G92243	222
G92281 thru G92283	222
G92341 thru G92343	222
G92381 thru G92383	222
HCSS	74
HFLW	75
HFMS	74
HHCS	74
HHXN	75
HLKW	75
HOCW	76
HRCN	75
HRMS	74
HSHS	74
HSQN	75
HSQN050	144
HTHR	75
J1205 thru J1280	117
K1062	76
K1063	76
K1064	76
LS 410	106
LS 500	106
M2037	133
M2050	133
M2137	133
M2150	133
M2250	133
M2350	133
M24	144
M2506	144
M2508	144
M2510	144
M2512	144
M2523	144
M2524	144
MU025 thru MU400	111
P1000	24
P1000 DS	24
P1000 EA	211
P1000 H3, P1000 HS, P1000 KO, P1000 SL	24
P1000 SS	209
P1000 T	24
P1000HS SS	209

P1000T SS	209
P1001	24
P1001 3	27
P1001 A, P1001 A3, P1001 B, P1001 B3	27
P1001 C, P1001 C3, P1001 C41, P1001 D3	27
P1001 EA	211
P1001 SS	209
P1001 T	27
P1003	27
P1004 A	27
P1006-0832	73
P1006-1024	73
P1006-1420	73
P1006T1420	73
P1007	73
P1008	73
P1008T	73
P1009	73
P1010	73
P1010T	73
P1012	73
P1012S	73
P1016	73
P1023	73
P1023S	73
P1024	73
P1024S	73
P1026	82
P1028	82
P1029	84
P1031	82
P1033	83
P1034	83
P1035	84
P1036	81
P1037	83
P1038	83
P1043A	88
P1044	88
P1045	86
P1046A	88
P1047	87
P1048, P1049, P1050	88
P1062	81
P1063	81
P1064	81
P1065	81
P1066	81
P1067	81
P1068	82
P1075	91
P1100	30
P1100 HS, P1100 KO, P1100 SL	30