 
 


 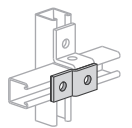
 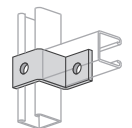
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 
 





 

 
 
 
 
 

 
 
 
 
 
 
 
 
 
 
 
 
 
 
 


 

 





 
 
 
 



General Fittings (cont.)						
						
PS 711..... 57	PS 928..... 57	PS 609..... 57	PS 647..... 56	PS 692..... 56	PS 2523..... 56	PS 2532..... 56
						
PS 3060..... 56	PS 613..... 57	PS 679..... 57	PS 2648..... 57	PS 687A, B & C..... 58	PS 710..... 57	PS 2119..... 57
						
PS 721..... 58	PS 929..... 58	PS 978..... 58	PS 709..... 58	PS 733..... 58	PS 678..... 58	PS 677..... 58
						
PS 734..... 58	PS 735..... 58	PS 623..... 58	PS 993..... 59	PS 922 R or L..... 59	PS 2117 R or L..... 59	PS 2128 R or L..... 60
						
PS 631..... 59	PS 644..... 59	PS 645..... 59	PS 629..... 59	PS 516, PS 646..... 59	PS 804..... 59	PS 704..... 59
						
PS 1004..... 59	PS 2129 R or L..... 60	PS 665..... 60	PS 666..... 60	PS 667..... 60	PS 2514..... 60	PS 670..... 61
						
PS 668..... 60	PS 821..... 60	PS 913..... 60	PS 923..... 60	PS 945..... 60	PS 669..... 61	PS 2514..... 60
						
PS 3013 & SQ..... 61	PS 3025 & FL..... 61	PS 3033 & SQ..... 61	PS 3040..... 61	PS 2064..... 61	PS 3064..... 62	PS 3029..... 62
						
PS 3041..... 61	PS 2521..... 62	PS 2522..... 62	PS 2528 1..... 62	PS 2528..... 62	PS 2524..... 62	PS 2525..... 62
						
PS 626..... 63	PS 661 T1 & T2..... 63	PS 808 T1 & T2..... 63	PS 651..... 63	PS 809..... 63	PS 708..... 63	PS 3164..... 64

# FITTINGS


Finish: Painted Green or Electro-galvanized Order By: No., Size and Finish



## PS 3029 - Double-Column Post Base

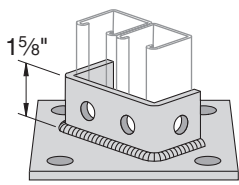


Use With: PS 100, PS 200 2T3, PS 210 2T3

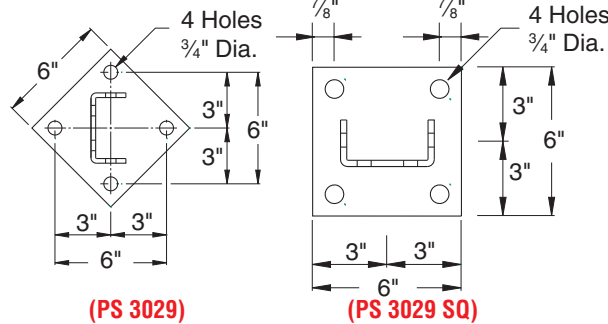


Weight/100 pcs: 325 lbs.

## PS 3064 - Double-Column Post Base

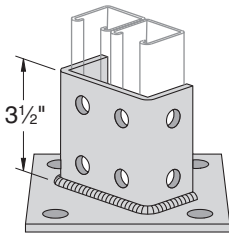


Use With: PS 100, PS 200 2T2, PS 200 2T3, PS 200 2T4 and PS 200 2T5

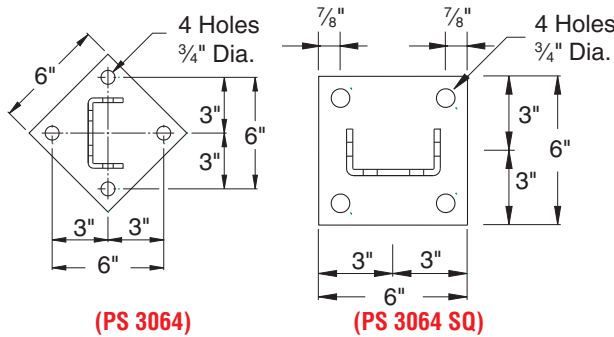


Weight/100 pcs: 408 lbs.

## PS 2521 - Two-Wheel Trolley

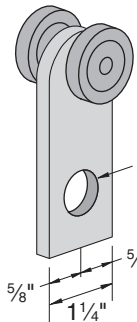

Hole  $\frac{9}{16}$ " Dia.

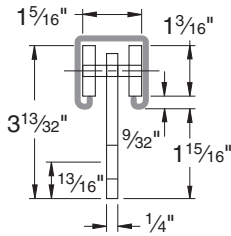

**Material:** Carbon Steel Wheels have stainless steel ball bearings

**Finish:** Electro-Galvanized


**Use With:** PS 200

**Load Rating:** 300 lbs.

FPM	RPM	Design Load In PS 200 Lbs
180	600	150
90	300	225
30	100	437

Weight/100 pcs: 46 lbs.

## PS 2528 - Trolley Beam Standard Support

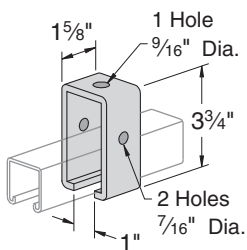


Use With: PS 200, PS 210

Load Rating: 600 lbs.

Weight/100 pcs: 102 lbs.

## PS 2528 1 - Trolley Beam Heavy Support and Track Joiner

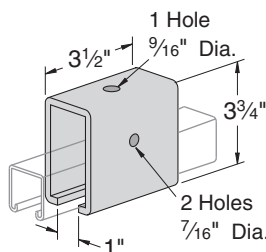


Use With: PS 200, PS 210


Load Rating: 2,500 lbs.

Weight/100 pcs: 220 lbs.

## PS 2524 - Two-Bearing Light Duty Trolley

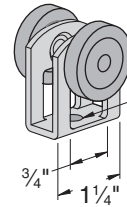


Load Rating: 50 lbs.

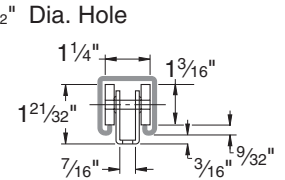


Weight/100 pcs: 21 lbs.

## PS 2525 - Four-Bearing Light Duty Trolley

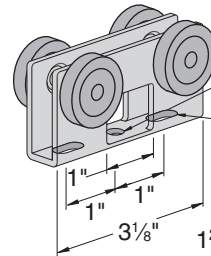


Load Rating: 100 lbs.

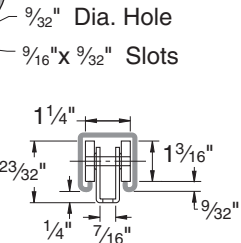

Weight/100 pcs: 55 lbs.

## PS 2522 - Four-Wheel Trolley

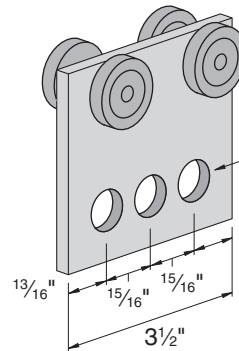

3 Holes  $\frac{9}{16}$ " Dia.

**Material:** Carbon Steel Wheels have stainless steel ball bearings

**Finish:** Electro-Galvanized

**Use With:** PS 200

**Load Rating:** 600 lbs.

FPM	RPM	Design Load In PS 200 Lbs
180	600	300
90	300	450
30	100	600

Weight/100 pcs: 110 lbs.