 
 





### Pipe & Conduit Clamps




P1109 - Pg 108



 P1211 - Pg 109




P1425 - Pg 109

 


P2024 - Pg 110



 
P1563 - Pg 109




P2008 - Pg 109

 


P2558 - Pg 110

 


P3409 - Pg 111

 


MU025 - Pg 111

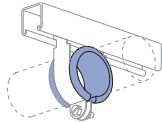


P2600 - Pg 112

 


004T008 - Pg 113

 


004M007 - Pg 114

 

UB1/2PA - Pg 115

 


CG-10 - Pg 116

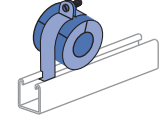


PUX3834 - Pg 116


### Pipe Rollers

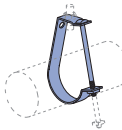


J1205 - Pg 117

 


P2474 - Pg 117

 

P2474-1 - Pg 118

 


P2475 - Pg 118

 


P2476 - Pg 119


### Pipe Brackets

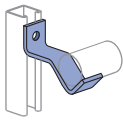

P2481 - Pg 119

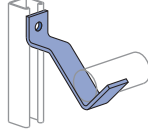


P2482 - Pg 119

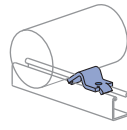

P2243 - Pg 119

### P1109 THRU P1126

### PIPE CLAMPS FOR RIGID STEEL CONDUIT

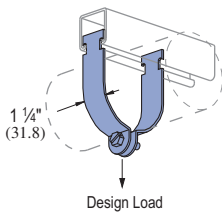

Part No.	Conduit Size In	O.D. Size In (mm)	Thickness Gauge (mm)	Wt/100 pcs Lbs (kg)	Design Load Lbs (kN)
P1109	3/8	0.675 17.1	16 1.5	10 4.5	400 1.78
P1111	1/2	0.840 21.3	16 1.5	11 5.0	400 1.78
P1112	3/4	1.050 26.7	14 1.9	15 6.8	600 2.67
P1113	1	1.315 33.4	14 1.9	17 7.7	600 2.67
P1114	1 1/4	1.660 42.2	14 1.9	19 8.6	600 2.67
P1115	1 1/2	1.900 48.3	12 2.7	29 13.2	800 3.56
P1117	2	2.375 60.3	12 2.7	34 15.4	800 3.56

Part No.	Conduit Size In	O.D. Size In (mm)	Thickness Gauge (mm)	Wt/100 pcs Lbs (kg)	Design Load Lbs (kN)
P1118	2 1/2	2.875 73.0	12 2.7	40 18.1	800 3.56
P1119	3	3.500 88.9	12 2.7	47 21.3	800 3.56
P1120	3 1/2	4.000 101.6	11 3.0	62 28.1	1,000 4.45
P1121	4	4.500 114.3	11 3.0	67 30.4	1,000 4.45
P1123	5	5.563 141.3	11 3.0	80 36.3	1,000 4.45
P1124	6	6.625 168.3	10 3.4	102 46.3	1,000 4.45
P1126	8	8.625 219.1	10 3.4	130 59.0	1,000 4.45

Slotted hex head screw and nut included with EG or HG Finish.

1 5/8" Channel  
Telestrut  
Nuts & Hardware  
General Fittings  
Pipe/Conduit Supports  
Electrical Fittings  
Concrete Inserts  
Solar  
Unipier®