



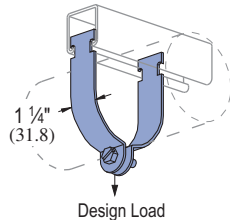

### P2024 THRU P2070-84

### PIPE CLAMPS FOR O.D. TUBING EG HG

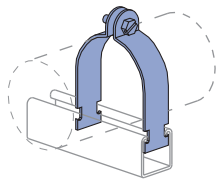

Slotted hex head screw and nut included with EG or HG Finish.


- P2024 - P2029 16 ga.
- P2030 - P2035 14 ga.
- P2037 - P2052 12 ga.
- P2053 - P2066 11 ga.
- P2067 - P2070-84 10 ga.

| Part Number | O.D. Size<br>In (mm) | Wt/100 pcs<br>Lbs (kg) | Design Load<br>Lbs (kN) |
|-------------|----------------------|------------------------|-------------------------|
| P2024       | ¼ (6.4)              | 8 (3.6)                | 400<br>(1.78)           |
| P2025       | ⅜ (9.5)              | 8 (3.6)                |                         |
| P2026       | ½ (12.7)             | 9 (4.1)                |                         |
| P2027       | ⅝ (15.9)             | 10 (4.5)               |                         |
| P2028       | ¾ (19.1)             | 11 (5.0)               |                         |
| P2029       | 7⁄8 (22.2)           | 12 (5.4)               |                         |
| P2030       | 1 (25.4)             | 14 (6.4)               | 600<br>(2.67)           |
| P2031       | 1 1⁄8 (28.6)         | 15 (6.8)               |                         |
| P2032       | 1 ¼ (31.8)           | 16 (7.3)               |                         |
| P2033       | 1 ½ (34.9)           | 17 (7.7)               |                         |
| P2034       | 1 ¾ (38.1)           | 18 (8.2)               |                         |
| P2035       | 1 ⅞ (41.3)           | 19 (8.6)               |                         |
| P1430       | 1 ¾ (44.5)           | 29 (13.2)              | 800<br>(3.56)           |
| P2037       | 1 ⅞ (47.6)           | 28 (12.7)              |                         |
| P2038       | 2 (50.8)             | 31 (14.1)              |                         |
| P2039       | 2 1⁄8 (54.0)         | 32 (14.5)              |                         |
| P2040       | 2 ¼ (57.2)           | 33 (15)                |                         |
| P1117       | 2 ⅝ (60.3)           | 34 (15.4)              |                         |
| P2042       | 2 ½ (63.5)           | 35 (15.9)              |                         |
| P2043       | 2 ⅞ (66.7)           | 37 (16.8)              |                         |
| P2044       | 2 ¾ (69.9)           | 38 (17.2)              |                         |
| P1118       | 2 ⅞ (73.0)           | 40 (18.1)              |                         |
| P2046       | 3 (76.2)             | 41 (18.6)              |                         |
| P2047       | 3 ⅛ (79.4)           | 43 (19.5)              |                         |
| P2048       | 3 ¼ (82.6)           | 45 (20.4)              |                         |
| P2049       | 3 ⅝ (85.7)           | 46 (20.9)              |                         |
| P1119       | 3 ½ (88.9)           | 47 (21.3)              |                         |
| P2051       | 3 ⅞ (92.1)           | 56 (25.4)              | 1000<br>(4.45)          |
| P2052       | 3 ¾ (95.3)           | 58 (26.3)              |                         |
| P2053       | 3 ⅞ (98.4)           | 60 (27.2)              |                         |
| P1120       | 4 (101.6)            | 62 (28.1)              |                         |
| P2055       | 4 ⅛ (104.8)          | 62 (28.1)              |                         |
| P2056       | 4 ¼ (108.0)          | 64 (29.0)              |                         |
| P2057       | 4 ⅝ (111.1)          | 66 (29.9)              |                         |
| P1121       | 4 ½ (114.3)          | 67 (30.4)              |                         |
| P2059       | 4 ⅞ (117.5)          | 70 (31.8)              |                         |
| P2060       | 4 ¾ (120.7)          | 72 (32.7)              |                         |


| Part Number | O.D. Size<br>In (mm) | Wt/100 pcs<br>Lbs (kg) | Design Load<br>Lbs (kN) |
|-------------|----------------------|------------------------|-------------------------|
| P2061       | 4 ⅞ (123.8)          | 73 (33.1)              | 1000<br>(4.45)          |
| P2062       | 5 (127.0)            | 74 (33.6)              |                         |
| P2063       | 5 1⁄8 (130.2)        | 76 (34.5)              |                         |
| P2064       | 5 ¼ (133.4)          | 77 (34.9)              |                         |
| P2065       | 5 ⅝ (136.5)          | 78 (35.4)              |                         |
| P2066       | 5 ¾ (140.0)          | 79 (35.8)              |                         |
| P2067       | 5 ⅞ (142.9)          | 88 (39.9)              |                         |
| P2068       | 5 ¾ (146.1)          | 90 (40.8)              |                         |
| P2069       | 5 ⅞ (149.2)          | 92 (41.7)              |                         |
| P2070       | 6 (152.4)            | 94 (42.6)              |                         |
| P2070-61    | 6 ⅛ (155.6)          | 96 (43.5)              |                         |
| P2070-62    | 6 ¼ (158.8)          | 98 (44.5)              |                         |
| P2070-63    | 6 ⅝ (161.9)          | 99 (44.9)              |                         |
| P2070-64    | 6 ½ (165.1)          | 100 (45.4)             |                         |
| P1124       | 6 ⅞ (168.3)          | 102 (46.3)             |                         |
| P2070-66    | 6 ¾ (171.5)          | 104 (47.2)             |                         |
| P2070-67    | 6 ⅞ (174.6)          | 106 (48.1)             |                         |
| P2070-70    | 7 (177.8)            | 108 (49.0)             |                         |
| P2070-71    | 7 ⅛ (181.0)          | 110 (49.9)             |                         |
| P2070-72    | 7 ¼ (184.2)          | 112 (50.8)             |                         |
| P2070-73    | 7 ⅝ (187.3)          | 114 (51.7)             |                         |
| P2070-74    | 7 ½ (190.5)          | 116 (52.6)             |                         |
| P2070-75    | 7 ⅞ (193.7)          | 117 (53.1)             |                         |
| P2070-76    | 7 ¾ (196.9)          | 119 (54.0)             |                         |
| P2070-77    | 7 ⅞ (200.0)          | 121 (54.9)             |                         |
| P2070-80    | 8 (203.2)            | 123 (55.8)             |                         |
| P2070-81    | 8 ⅛ (206.4)          | 125 (56.7)             |                         |
| P2070-82    | 8 ¼ (209.6)          | 126 (57.2)             |                         |
| P2070-83    | 8 ⅝ (212.7)          | 128 (58.1)             |                         |
| P2070-84    | 8 ½ (215.9)          | 129 (58.5)             |                         |
| P1126       | 8 ⅞ (219.1)          | 130 (59.0)             |                         |

### P2558-5 THRU P2558-60

### SINGLE PIECE PIPE STRAP EG GR HG

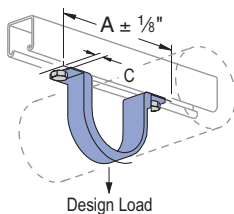

Supporting Rib on P2558-60

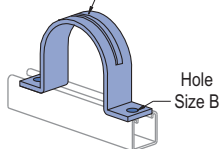

Hardware sold separately.

| Part No. | Nom. Pipe Size In | A In (mm)    | "B" In (mm)  | C In (mm)   | Thickness In (mm) | Wt/100 pcs Lbs (kg) | Design Load Lbs (kN) |
|----------|-------------------|--------------|--------------|-------------|-------------------|---------------------|----------------------|
| P2558-05 | ½                 | 2 ⅞<br>73.0  | 7.1          | 11.1        | 3.2               | 23<br>10.4          | 500<br>2.22          |
| P2558-07 | ¾                 | 3 ⅝<br>79.4  |              |             |                   | 26<br>11.8          |                      |
| P2558-10 | 1                 | 3 ⅞<br>85.7  |              |             |                   | 31<br>14.1          |                      |
| P2558-12 | 1 ¼               | 3 ¾<br>95.3  | 35<br>15.9   |             |                   |                     |                      |
| P2558-15 | 1 ½               | 3 ⅞<br>98.4  | 39<br>17.7   |             |                   |                     |                      |
| P2558-20 | 2                 | 5 ¾<br>146.1 | 7 ⅞<br>11.1  | 1 ⅞<br>17.5 | ¼<br>6.4          | 94<br>42.6          |                      |
| P2558-25 | 2 ½               | 6 ¼<br>158.8 |              |             |                   | 114<br>51.7         |                      |
| P2558-30 | 3                 | 6 ⅞<br>174.6 |              |             |                   | 133<br>60.3         |                      |
| P2558-35 | 3 ½               | 7 ⅞<br>187.3 |              |             |                   | 152<br>68.9         |                      |
| P2558-40 | 4                 | 7 ⅞<br>200.0 |              |             |                   | 176<br>79.8         |                      |
| P2558-50 | 5                 | 9<br>228.6   |              |             |                   | 198<br>89.8         |                      |
| P2558-60 | 6                 | 10<br>254.0  | 225<br>102.1 |             |                   |                     |                      |