


Bare Armored Ground Cable Technical Specifications

Specification Description

Specification	Bare Armored Ground
Armor	Galvanized interlocked steel
Conductors	Solid 8 AWG and 6 AWG 7 Strand 4 AWG

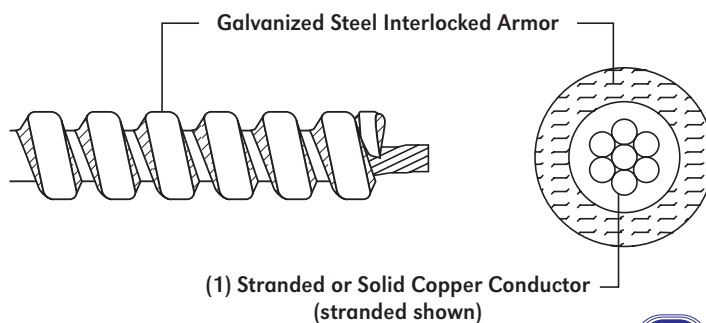

References & Ratings

- UL 467 E82631
- NEC® 250.118

Product Codes, Trade Sizes, Conductors, Packaging & Weights

Product Code		Trade Size	Length (feet)		Approx. Weight/1000 Feet (lbs.)	Armor Minimum O.D. (inches)
Coil	Reel		Coil	Reel		
1301-42-00	1301-60-00	8-1 Solid	250'	1000'	136	tba
1302-42-00	1302-60-00	6-1 Solid	250'	1000'	168	tba
1303-42-00	1303-45-00	4-1 Stranded	250'	500'	241	tba

NOTE: All dimensions and weights are subject to normal manufacturing tolerances